




Pass and Seymour
TradeMaster® 3-Gang Nylon Wall Plate, 3 Decorator Openings, Red
Part No. TP263RED

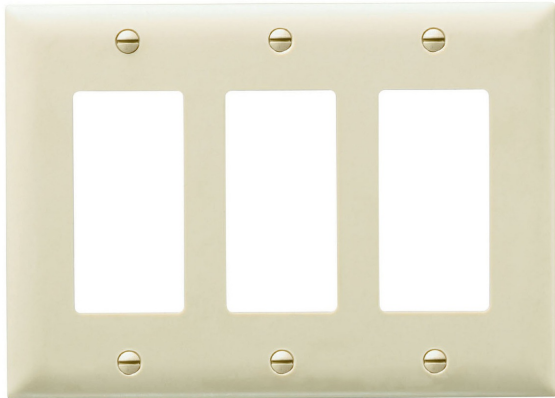

The TradeMaster® thermoplastic 3-gang decorator wall plate provides maximum durability in plastic wall plates. Self-extinguishing nylon construction makes these wall plates virtually unbreakable. They are 3/16 of an inch higher and wider than typical plastic wall plates - not enough to be apparent to the eye, but the extra size cuts cost by reducing dry wall rework.

Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

Specifications

General Info

| | | | |
|--------------------|-------------------------|-----------------|--------------|
| Product Line | Pass & Seymour | Color | Red |
| Finish | Matte | UPC Number | 785007275599 |
| Country Of Origin | United States | Construction | Plastic |
| Wall Plate Size | Standard Size | Wall Plate Type | Decorator |
| Application Sector | Commercial, Residential | Standard | CSA, UL514 |
| Warranty Type | 1-Year Limited Warranty | Type | Wall Plate |

Dimensions

| | | | |
|------------------|----------|------------------|---------|
| Product Width US | 6.563 in | Product Depth US | 0.25 in |
|------------------|----------|------------------|---------|

| | |
|-------------------|-----------|
| Product Height US | 4.6875 in |
|-------------------|-----------|

Listing Agencies / 3rd Party Agencies

| | | | |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | 143222 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

Additional Information

| | |
|-------------------------------|-----|
| Product Environmental Profile | Yes |
|-------------------------------|-----|

Technical Information

| | | | |
|----------------|----------|-----------------|-------------|
| Thickness | 0.07 in | Number of Gangs | 3 |
| Indoor/Outdoor | Indoor | Mounting Type | Box Mounted |
| Orientation | Vertical | | |