




Pass and Seymour  
TradeMaster® 2-Gang Nylon Wall Plate, 2 Duplex Receptacle Openings, Ivory  
Part No. TP82I

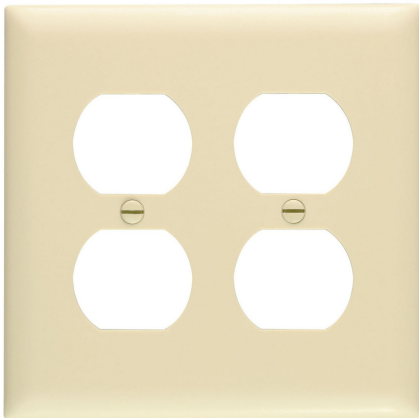

Trademaster Plate,double gang and duplex plate, is molded of rugged, practically indestructible self-extinguishing nylon. It is preferred for hospital, industrial, institutional, and other high-abuse applications. Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

## Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory
Finish	Matte	UPC Number	785007275223
Country Of Origin	United States	Construction	Plastic
Wall Plate Size	Standard Size	Wall Plate Type	Duplex Receptacle
Application Sector	Commercial, Residential	Standard	CSA, UL514
Warranty Type	1-Year Limited Warranty	Type	Wall Plate

### Dimensions

Product Width US	4.75 in	Product Depth US	0.25 in
------------------	---------	------------------	---------

Product Height US	4.6875 in
-------------------	-----------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	143222	cULus Listed	Yes
---------------------	--------	--------------	-----

Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

Technical Information

Thickness	0.07 in	Number of Gangs	2
Indoor/Outdoor	Indoor	Mounting Type	Strap Mounted
Orientation	Vertical		