




Pass and Seymour
Duplex Receptacle Openings, Two Gang, Light Almond
Part No. TP82LA

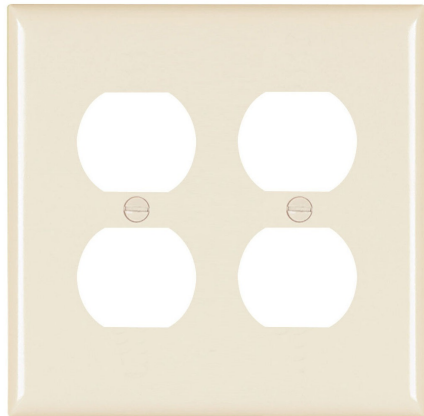

Trademaster Plate, double gang and duplex plate, is molded of rugged, practically indestructible self-extinguishing nylon. It is preferred for hospital, industrial, institutional, and other high-abuse applications. Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

For covering patents, see www.legrand.us/patents.

Specifications

General Info

Product Line	Pass & Seymour	Country Of Origin	United States
Wall Plate Type	Outlet	Application Sector	Residential/Commercial
Standard	CSA, UL514		

Dimensions

Product Width US	4.75 in	Product Depth US	0.25 in
Product Height US	4.6875 in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	143222	cULus Listed	Yes
---------------------	--------	--------------	-----

Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

Technical Information

Cutout	Receptacle	Thickness	0.07 in
--------	------------	-----------	---------

Number of Gangs	2	Mounting Type	Exposed Screws
-----------------	---	---------------	----------------
