




Pass and Seymour  
3.1A Spec Grade USB Outlet, Type A/C, 20A, Tamper-Resistant, Light Almond  
Part No. TR20USBACLA

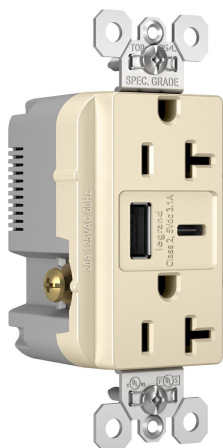

20A 125V Tamper-Resistant Receptacle with two 3.1A USB charging ports  
Type A and C

## Features & Benefits

Two drive screws anchor strap to back body and face where abrupt removal torque is greatest.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Light Almond
UPC Number	785007181630	Country Of Origin	China
Number of Receptacles	2	Features	USB-A Charging, USB-C Charging
Outlet Type	Tamper-Resistant, USB-Charging	Application Sector	Commercial, Residential
Standard	FEDSPEC	Type	Outlet

### Dimensions

Product Width US	1.693 in	Product Depth US	1.425 in
Product Height US	2.677 in		

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

---

Additional Information

---

Product Environmental Profile    Yes

---

Technical Information

---

USB Amperage	3.1 A	Number of USBs	2
USB Power Output	15 W	Amperage	20 A
Number of Poles	Double Pole	Indoor/Outdoor	Indoor

---