




radiant Collection
Spec Grade 30W USB Outlet, Type C, 20A, Tamper-Resistant, White
Part No. TR20USBDPW

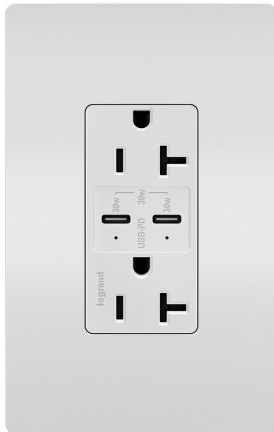

Made to deliver a leading 30 Watts of power and featuring two built-in Type-C USB connections, this solution adds advanced Power Delivery to the industry-leading amperage of our USB line. The result is a faster, future-proof option for convenient in-wall charging, specially designed to optimize performance for your Power Delivery-enabled devices. Easily replace a traditional outlet in as little as ten minutes to gain the modern functionality of intelligent charging for maximized speeds, complete with multi-layered overcurrent protection to keep the outlet and your devices safe from damage.

Features & Benefits

Charge the latest devices up to 2X as fast, thanks to 6 amps and a whopping 30W of power courtesy of advanced Power Delivery

Provides fast and convenient built-in charging through two future-proof USB Type-C ports, accommodating new and upcoming devices without an adapter

Includes multiple layers of overcurrent protection, ensuring the outlet and your favorite devices can charge at optimal levels without risk of damage

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect

More color options available to fit any style, including finishes to match current hardware and lighting trends

Built for intelligent charging, the outlet detects and delivers the precise amount of power needed to maximize charging speeds

Helpful indicator light lets you see charging status at a glance. Light glows yellow while charging is in progress, and shows green once the device battery is sufficiently charged

All Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty

Replaces a traditional outlet easily, in as little as 10 minutes, with features like scalloped cover design and posted side-wire terminal screws for faster installation

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007297744
Country Of Origin	China	Number of Receptacles	2
Features	USB-C Charging	Outlet Type	Tamper-Resistant, USB-Charging
Application Sector	Commercial	Wall Plate Included	No

Warranty Type	1-Year Limited Warranty		
Dimensions			
Product Width US	1.69 in	Product Depth US	1.42 in
Product Height US	2.63 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E140596	cULus Listed	Yes
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Operating Temperature Min	-40 °C	Is Tamper-Resistant	Yes
Connection Location	Side Only	USB Wattage	30 W
USB Amperage	6 A	Frequency Rating	60 Hz
Number of USBs	2	Number of Wires	3
Operating Temperature Max	60 °C	Amperage	20 A
Number of Poles	Double Pole	Wire Size	14 - 10 AWG
Indoor/Outdoor	Indoor	NEMA Configuration Code	5-20R
Mounting Type	Box	Operating Temperature	-40°-60°C
Wire Connection Type	Screw Terminals	Voltage	125.0 V
Environmental Conditions	95% (relative humidity, non-condensing)		