




Pass and Seymour
15A 125V Hard-Use Spec-Grade Plug Load Controllable Duplex Receptacle, White
Part No. TR5262CHW

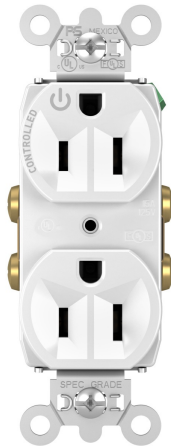

Permanent controlled receptacle marking allows for long-lasting, easy identification of controlled receptacle for end-users. NEMA-approved and compliant with NEC, CA Title 24, and ASHRAE Energy Efficiency Standard 90.1.

Features & Benefits

Can be wired to any number of system-based or stand-alone plug load control solutions.

Auto-ground clip assures positive ground.

.032 inch thick, brass, triple-wipe power contacts for lasting retention.

Permanent controlled receptacle markings using abrasion resistant ink.

Two drive screws anchor strap to back body and face where abrupt removal torque is strongest.

Tri-drive brass-plated terminal screws. Two back-wire holes for more wiring flexibility.

Strap tabs wrap around face to prevent strap from separating from face and back body.

CH Version Only: Split circuit tab broken at the factory, allowing half of the receptacle to be controlled.

For covering patents, see www.legrand.us/patents.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007050950
Country Of Origin	Mexico	Number of Receptacles	2
Outlet Type	Energy Saving On/Off	Application Sector	Commercial
Standard	FEDSPEC	Type	Outlet

Dimensions

Product Width US	1.322 in	Product Depth US	1.13 in
------------------	----------	------------------	---------

Product Height US	2.63 in
-------------------	---------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	140596	cULus Listed	Yes
---------------------	--------	--------------	-----

Technical Information

Amperage	15 A	Number of Poles	Double Pole
----------	------	-----------------	-------------

Indoor/Outdoor	Indoor
----------------	--------