




Wiremold  
2400D RADIUS Divided Flat Elbow Fitting  
Part No. V2411DFO

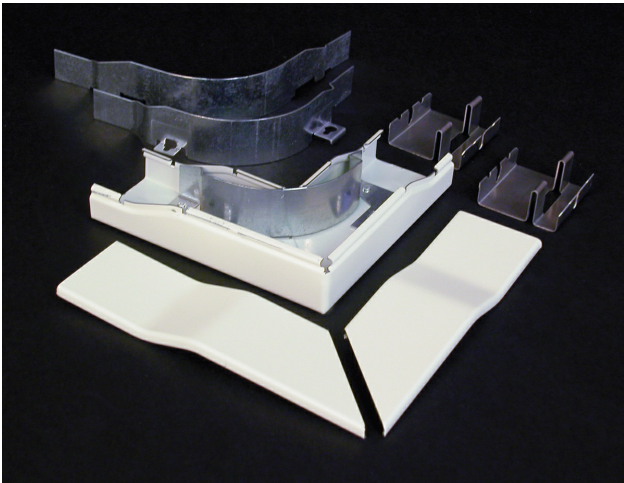

90 degree flat elbow with integral dividers. Provides 2" (51mm) full capacity cable bend radius control for fiber optic and UTP/STP cable installations. Ideal for lay-in or pull-through installations. Two couplings included.

## Features & Benefits

90 degree flat elbow with integral dividers. Provides 2" (51mm) full capacity cable bend radius control for fiber optic and UTP/STP cable installations. Ideal for lay-in or pull-through installations. Two couplings included.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776569582
Country Of Origin	United States	Application Sector	Residential/Commercial
Standard	cULus Listed Raceway: FileE4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.	Type	Raceway

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E41751	cULus Listed	Yes
---------------------	--------	--------------	-----

### Buy American Act Compliance

NAFTA	Yes
-------	-----

### Additional Information

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----

---

## Technical Information

---

Voltage	600.0 V
---------	---------

---