




**On-Q**  
**RJ45 Cat 6 Coupler Keystone Insert, White**  
Part No. WP3452WHV1

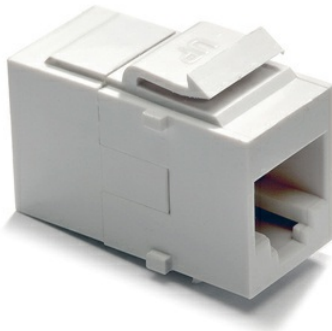

The Cat 6 RJ45 Keystone Coupler couples two high-speed network cables. The female to female coupler meets the EIA/TIA 568A Category 6 specifications.

## Features & Benefits

Provides superior gigabit performance without punch-down termination

Supports up to 10 gigabit Ethernet connection

No tools required

Exceeds Category 6 component standard: Ensures standards compliance

## Specifications

### General Info

Color	White	UPC Number	804428065968
-------	-------	------------	--------------

Country Of Origin	Taiwan, Province Of China	Product Line	On-Q
-------------------	---------------------------	--------------	------

Finish	Matte	Package Quantity	1
--------	-------	------------------	---

Application Sector	Residential	Type	Coupler
--------------------	-------------	------	---------

Standard	CSA, cULus, RoHS, ANSI/UL 1863, Flame-Retardant Plastic UL 94V-0
----------	---------------------------------------------------------------------

### Technical Information

Category Performance Rating	Cat 6	Operating Temperature	14 to 140 F
-----------------------------	-------	-----------------------	-------------

Cable Type	Cat 6	Gauge	22 to 24 AWG
------------	-------	-------	--------------

---

Bandwidth

100 MHz

Environmental Conditions

0 to 93 (relative  
humidity, non-  
condensing) pct

---

Termination Style

Coupler

---