




Pass and Seymour
Wide Slide Series CFL/LED/Incandescent Single Pole/3-Way Slide Dimmer, Non-Preset, White
Part No. WSCL450W

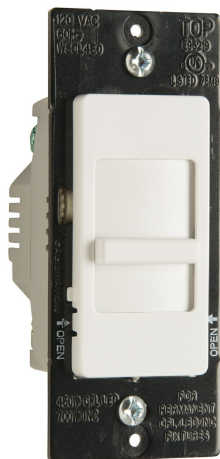

Works with select dimmable CFL/LED or incandescent lighting loads and features a sleek, sculpted ergonomic design for smooth, easy operation and precise control.

Features & Benefits

Convenient Operation - Combines ON/OFF Decorator-style switch with separate slider for dimming control	Constant memory returns lights to previous level after a power failure
Sleek, ergonomic design that matches well with other decorator products	Higher ratings
Single-pole operation	Screw-pressure-plate back wire terminals save time, space and money
Rating: 450W LED & CFL: 700W Incandescent: 120VAC 60Hz	

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007040425
Country Of Origin	China	Product Series	Decorator
Features	Color Change Kit	Switch Type	Slider
Number of Switches	1	Application Sector	Residential
Standard	cULus, RoHS	Warranty Type	Limited Lifetime Warranty

Dimensions

Product Width US	1.75 in	Product Depth US	1.25 in
------------------	---------	------------------	---------

Product Height US	4.25 in
-------------------	---------

Technical Information

Preset	No	Load Rating	120V 450W (CFL), 120V 450W (LED), 120V 700W (Halogen), 120V 700W (Incandescent)
Dimming Compatibility	Forward Phase	Frequency Rating	60 Hz
Number of Poles	Single Pole	Wire Size	#14 - #10 AWG
Requires Neutral Wire	No	Indoor/Outdoor	Indoor
Mounting Type	Wall Box	Wire Connection Type	Screw Terminals
Voltage	120 VAC	Load Type	CFL, Halogen, Incandescent, LED
Environmental Conditions	Humidity: Less than 95% non condensing		