
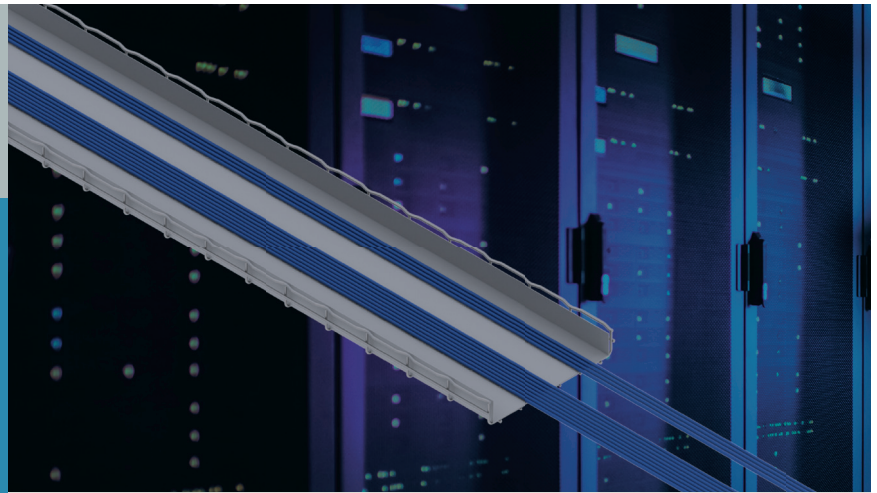


INSERTS FOR WIRE MESH TRAY

Smooth.
Secure.
Superior.


When it comes to creating smooth cable pathways, you should never have to sacrifice form for function.

Inserts for Wire Mesh Tray by Legrand help to easily create highly functional and visually pleasing cable tray installations that can be updated and expanded as your data center facility evolves. Each insert seamlessly integrates into new or existing systems for a smooth, professional appearance.

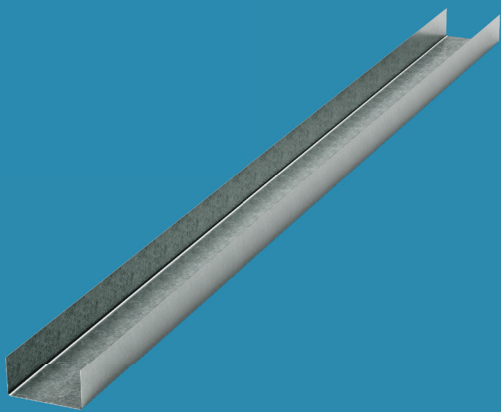

BASIC: Plastic Inserts

- Available as bottom-only or bottom with perforated sides
- Bottom-only insert fits 100- to 600-millimeter-wide tray
- Bottom with sides insert fits CF54, CF105 and CF150 trays in widths from 100 to 600 millimeters
- 17-millimeter thickness creates a smooth cable pathway
- Easy to install and can be cut to fit specific tray configurations
- Packaged in 200-foot rolls

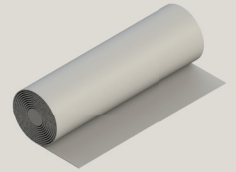

PREMIUM: Metal Inserts

- Available with or without sides
- Protects cables from tray pressure points
- Bend-over tabs secure insert to tray (flat inserts only)
- Flat insert comes in 2- to 5-foot lengths to cover one 10-foot section of tray
- Insert with sides comes in 10-foot lengths
- Easy to install and can be adjusted to accommodate changes to system infrastructure
- Creates a more professional, aesthetically pleasing appearance than plastic

PRODUCT INFORMATION

Steel Insert (Bottom Only)	PG	BL	Compatible Wire Mesh Tray	Plastic Insert (Bottom Only)	PG	BL	Compatible Wire Mesh Tray
INSERT 100	M	M	CF54/100XX	INSERTPP100	M	M	CF54/100XX
INSERT 150	M	M	CF54/150XX	INSERTPP150	M	M	CF54/150XX
INSERT 200	M	M	CF54/200XX	INSERTPP200	M	M	CF54/200XX
INSERT 300	S	S	CF54/300XX	INSERTPP300	M	M	CF54/300XX
INSERT 450	S	M	CF54/450XX	INSERTPP450	M	M	CF54/450XX
INSERT 500	M	M	CF54/500XX	INSERTPP500	M	M	CF54/500XX
INSERT 600	M	M	CF54/600XX	INSERTPP600	M	M	CF54/600XX

Steel Insert (Bottom w/ Sides)	PG	BL	Compatible Wire Mesh Tray	Plastic Insert (Bottom w/ Sides)	PG	BL	Compatible Wire Mesh Tray
INSERT54/50	M	M	CF54/50XX	INSERTPP54/100	M	M	CF54/100XX
INSERT54/100	M	M	CF54/100XX	INSERTPP54/150	M	M	CF54/150XX
INSERT54/150	M	M	CF54/150XX	INSERTPP54/200	M	M	CF54/200XX
INSERT54/200	M	M	CF54/200XX	INSERTPP54/300	M	M	CF54/300XX
INSERT54/300	M	M	CF54/300XX	INSERTPP54/450	M	M	CF54/450XX
INSERT54/450	M	M	CF54/450XX	INSERTPP54/500	M	M	CF54/500XX
INSERT54/500	M	M	CF54/500XX	INSERTPP54/600	M	M	CF54/600XX
INSERT54/600	M	M	CF54/600XX	INSERTPP105/100	M	M	CF105/100XX
INSERT105/100	M	M	CF105/100XX	INSERTPP105/150	M	M	CF105/150XX
INSERT105/150	M	M	CF105/150XX	INSERTPP105/200	M	M	CF105/200XX
INSERT105/200	M	M	CF105/200XX	INSERTPP105/300	M	M	CF105/300XX
INSERT105/300	M	M	CF105/300XX	INSERTPP105/450	M	M	CF105/450XX
INSERT105/450	M	M	CF105/450XX	INSERTPP105/500	M	M	CF105/500XX
INSERT105/500	M	M	CF105/500XX	INSERTPP105/600	M	M	CF105/600XX
INSERT105/600	M	M	CF105/600XX	INSERTPP150/150	M	M	CF150/150XX
INSERT150/150	M	M	CF150/150XX	INSERTPP150/200	M	M	CF150/200XX
INSERT150/200	M	M	CF150/200XX	INSERTPP150/300	M	M	CF150/300XX
INSERT150/300	M	M	CF150/300XX	INSERTPP150/450	M	M	CF150/450XX
INSERT150/450	M	M	CF150/450XX	INSERTPP150/500	M	M	CF150/500XX
INSERT150/500	M	M	CF150/500XX	INSERTPP150/600	M	M	CF150/600XX
INSERT150/600	M	M	CF150/600XX				

S-Normally Stocked M-Made to Order