



PTTR26362HGCDW PTTR26362HGCHRED


PlugTail® Hard Use Hospital Grade Plug Load Tamper-Resistant Receptacles. The fastest, most consistent and reliable wiring devices — ever.

PTTR26362HGCDW, PTTR26362HGCHRED

Pass & Seymour® Plug Load Fed Spec, factory-terminated devices and connectors mean that device installation is the same regardless of skill level of the installer. The UL-Listed connectors are keyed to ensure proper wiring installation into each hospital grade receptacle. The connector simply snaps into the back of the device — no fussing with wires, stripping, or tightening screws. PlugTail devices are finger safe with no exposed terminals, so taping is not required. Now device installation is a snap!

These durable, dependable receptacles feature a permanently marked controlled device that meets all necessary energy code code requirements for NEC, IECC, Ashrae and Title 24. A sturdy mechanical shutter system helps prevent children from sticking objects into the receptacle. The toughest and safest hospital grade tamper-resistant receptacle available.

Features & Benefits

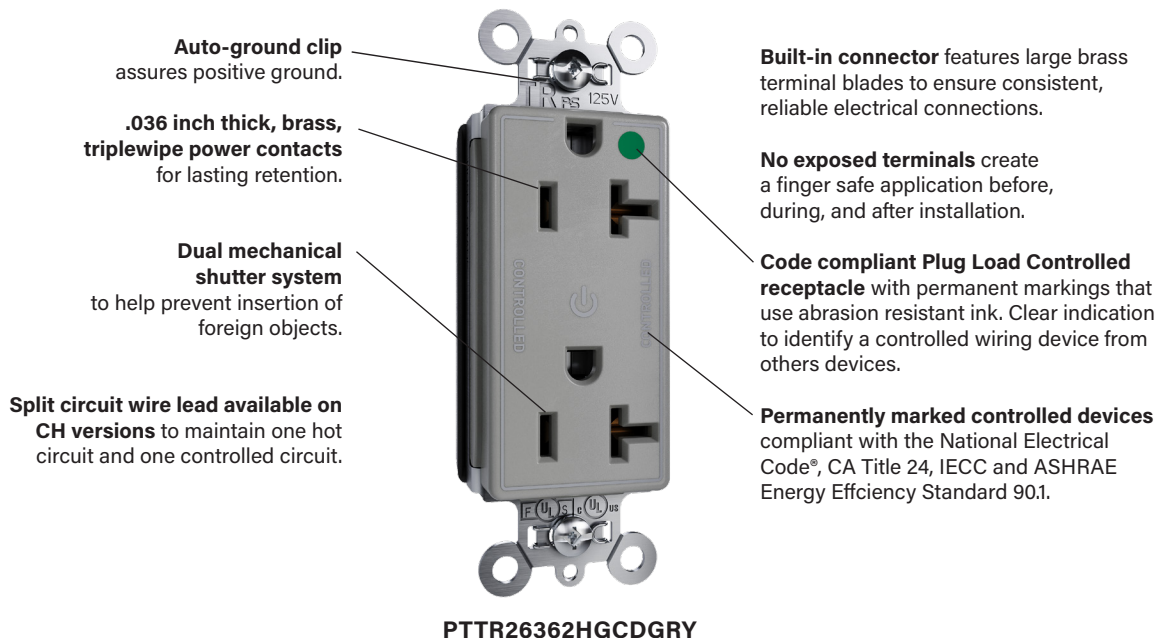

3rd Party Compliance



cUL Listed, File Number E140596, Standard UL498. UN SPSC: 3912406
Federal Specification WC596, Hospital Grade, CSA Listing: C22.2 No. 42.
CA Title 24, and ASHRAE Energy Efficiency Standard 90.1.2022 International Energy Conversation Code (IECC), 2024 NEC 2023, Part 6: Building Energy Efficiency Standard

Technical Information

Performance

Electrical

Dielectric Voltage	Withstands 2000V minimum
Maximum Working Voltage	125V
Current Interrupting	Certified for current interrupting at full-rated current (receptacle only)
Temperature Rise	Maximum 30° C temperature rise at full-rated current after 50 cycles of overload at 150% of rated current with direct current

Mechanical

PlugTail Connector Identification	#12 AWG, THHN, copper conductor, 6" leads, stripped, solid or stranded, for use with PlugTail Receptacles only
Product Identification	Ratings are a permanent part of the device

Environmental


Flammability	UL94 V2
Operating Temperature	Maximum continuous +60°C, minimum -40°C (without impact)

PlugTail Receptacle Materials


Face	Nylon
Body	PVC
Assembly Drive Screw	Zinc-Plated Steel
Tamper Shutter	Thermoplastic
Line Contacts	.036 688 Brass
Auto Ground Clip	Steel
Mounting Strap	.042 Zinc-Plated Steel
Mounting Screws	Tri-Drive Steel

PlugTail Connector Materials

Housing	Polycarbonate
---------	---------------

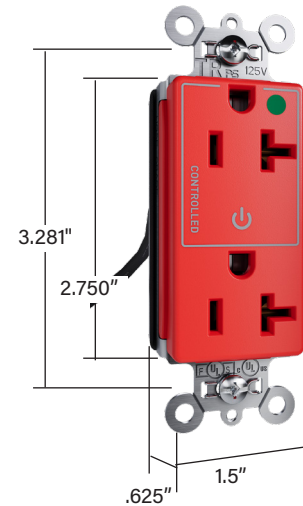

PTTR26362HGCHRED

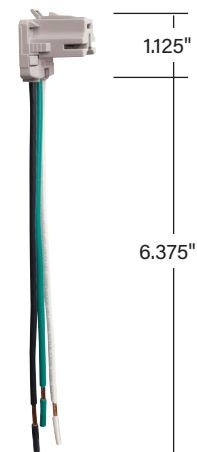

Warranty

1 Year

Country of Origin

Mexico

Buy America Act Status

Trade Agreement Act Compliant

Ordering Information

PlugTail® Hospital-Grade Tamper-Resistant Plugload Decorator Duplex Receptacles

Catalog Number	Control	Rating		Color	NEMA Config. No.
		A.	V.		
PTTR26362HGCHW	Half Controlled	20	125	White	5-20R
PTTR26362HGCDW	Dual Controlled	20	125	White	5-20R
PT26362HGCDW	Dual Controlled	20	125	White	5-20R
PTTR26362HGCHGRY	Half Controlled	20	125	Gray	5-20R
PTTR26362HGCDGRY	Dual Controlled	20	125	Gray	5-20R
PTTR26362HGCHRED	Half Controlled	20	125	Red	5-20R
PTTR26362HGCDRED	Dual Controlled	20	125	Red	5-20R




NEMA
5-20R

PlugTail® Connectors - Right Angle

Catalog Number	Wire Type	Length
PlugTail Connectors - Right Angle		
PTRA6SOL	Solid	6"
PTRA6STR	Stranded	6"
PTRA6SOLB25	Solid	25"
PTRA6STRB25	Stranded	25"
PlugTail Connectors - Right Angle with WAGO Connectors		
PTRA6SOLBP	Solid	6"
PTRA6STRBP	Stranded	6"

Catalog Number	Wire Type	Length
PlugTail Connectors - Right Angle with Ground Screw		
PTRA6SOLG	Solid	6"
PTRA6STRG	Stranded	6"

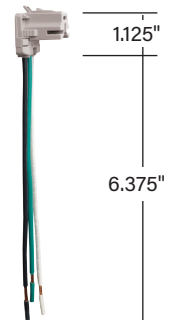

Vertical Markets

- Health Care

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.

