


# Smart Plug-in Tru Universal Dimmer, Zigbee 3.0

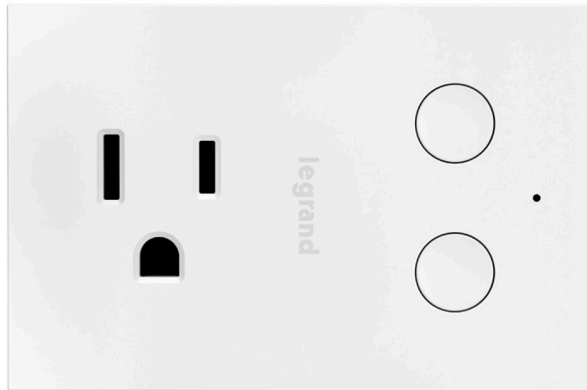

## Elevate every experience with Smart Plug-in Dimmers

WZ3P20

Usable on its own or combined with Legrand's complete Smart Hospitality offering, this plug-in dimmer lets you add floor and table lamps into the smart ecosystem of a guest's room. Select custom settings behind-the-scenes to power the device on/off or adjust light levels to match the room's occupancy status, helping enhance the guest experience while also managing energy and cost.

Tru-Universal Dimmers work with virtually any dimmable 120V bulb or fixture to offer precise light level control without the flicker.

Zigbee 3.0 Compliant and backwards compatible with systems supporting Zigbee 1.2HA. Available in White. Ideal for residential, multi-dwelling, commercial office and hospitality applications.

## FEATURES & BENEFITS

- Automatically turn lamps on/off, or adjust their light level, for an elevated guest experience.
- Pair with Smart Motion or Door Sensors with Zigbee 3.0 to create scenes based on occupancy levels.
- Integrate with the Smart Thermostat with Zigbee 3.0 Hub and other devices for a complete Smart Hospitality Solution.
- Installs easily – simply plug into a standard outlet; no wiring required.
- Works with virtually any dimmable 120V bulb.
- Self-calibrates when you select your lighting type, automatically setting the appropriate minimum voltage to eliminate flicker and poor performance.
- Compatible with Zigbee 3.0, and the older Zigbee 1.2HA

## APPLICATIONS

- Hospitality
- Residential
- Conference Rooms
- Office Spaces
- Light Commercial

## COMPLIANCE



cULus Listed, UL916, File E495025

FCC Class B Part 15, IC.

RoHS Compliant

**ORDERING INFORMATION**


---

CATALOG NUMBER	DESCRIPTION	RATING	NEMA	COMPLIANCE	COLORS	COO
WZ3P20	Zigbee 3.0 Plug- in Tru-Universal Dimmer	FWD - 1A LED/CFL FWD - 300W Inc/Hal//ELV FWD - 300 VA MLV REV - 300W Inc/Hal/ELV	5-15R 120 VAC, 60Hz		White	China

**TECHNICAL SPECIFICATIONS**

**3rd Party Compliance**

- cULus Listed, UL916, File E495025
- CSA-C22.2 Nos. 42-10 & 205
- Conforms to NEMA WD-1 and WD-6. FCC Class B Part 15, IC.
- IEEE 802.15.4, Zigbee 3.0 compliant channels 11-25
- Can be used to comply with ASHRAE 90.1 & 2016 Title 24 Space Area Control

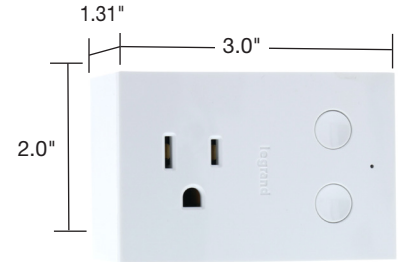

**Performance**

**ELECTRICAL**

Supply Voltage	120 VAC
Maximum Rated Load	FWD – 1A LED/CFL FWD – 300W Inc/Halogen/ELV FWD – 300 VA MLV REV – 300W INC/Halogen/ELV
Frequency	60Hz
Phase Control	Forward or Reverse (Configured via partner platform)
Installation	Single-Pole
Communication Frequency	2.4GHz

**ENVIRONMENTAL**

Usage	Indoor Use Only
Operating Temperature	32-104F   0-40C
Weight	.3 lbs

**Materials**

Paddle	Polycarbonate	Terminal	Brass
Back Body	Polycarbonate		

**Radio**

802.15.4	Certified IEEE 802.15.4 2.4GHz radio.
FCC ID	2AU5D982057
ICC ID	25764-982057

**Warranty**

Two Year Warranty

**NOTE:** All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



**NOTE:** The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.



**Legrand, North America**  
60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
[www.legrand.us](http://www.legrand.us)

**Canada**  
905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

FOLLOW US

