



Conveniently control your lights from anywhere

WWRL10x

Conveniently control your lights and power from anywhere using the Legrand Smart Lights mobile app, Amazon Alexa, the Google Assistant, and other popular control platforms. In the app, use Scenes to create the perfect ambiance in your home. With automated schedules, sync your outdoor lights with sunrise and sunset, or program to simulate occupancy while you're away. Legrand switches also use less energy than ordinary switches, with automated options available to promote enhanced energy savings.


Ideal for residential and light commercial applications, the Smart Switch, Wi-Fi is the simple solution to all your customers' smart lighting requirements



FEATURES & BENEFITS

- Control lights from smart phones and tablets with the Smart Lights app
- Schedule lights on/off automatically, group lights, and create Scenes
- Preset, Single-Pole and 3-Way operation
- Sleek, ergonomic design that matches today's styles
- Works with any 3-Way Switch
- White LED locator light glows when device is off for easy location in the dark
- Just ask Amazon Alexa or the Google Assistant to turn lights on
- Additional compatibility is Works with Google, Works with Amazon, OCF certified, Wi-Fi Certified

COMPLIANCE

 cULus Listed, UL508, CSA-C22.2 Nos. 14-13.
Conforms to NEMA WD-1 and WD-6. FCC Class B Part 15, IC. Works with Alexa
Works with the Google Assistant, OCF Certified, Wi-Fi Certified

RoHS Compliant



ORDERING INFORMATION

CATALOG NUMBER	DESCRIPTION	RATING	NEMA	COMPLIANCE	COLORS	COO
WWRL10WHCCV2	Smart Switch, Wi-Fi	Incandescent /halogen 1800W, Ballast 15A standard/electronic, LED 5A, 1/2 HP motor	120 VAC, 60Hz		White	China
WWRL10LACCV2	Smart Switch, Wi-Fi	Incandescent /halogen 1800W, Ballast 15A standard/electronic, LED 5A, 1/2 HP motor	120 VAC, 60Hz		Light Almond	China
WWRL10NICCV2	Smart Switch, Wi-Fi	Incandescent /halogen 1800W, Ballast 15A standard/electronic, LED 5A, 1/2 HP motor	120 VAC, 60Hz		Nickel	China

VERTICAL MARKETS

- Residential

COMPATIBILITY

OPEN CONNECTIVITY FOUNDATION™

DOWNLOAD THE APP

Smart Light


Download the iOS Legrand app



Download the Google Legrand app

TECHNICAL SPECIFICATIONS

3rd Party Compliance

cULus Listed, UL508, CSA-C22.2 Nos. 14-13.
 Conforms to NEMA WD-1 and WD-6. FCC Class B Part 15, IC. Works with Alexa
 Works with the Google Assistant, OCF Certified, Wi-Fi Certified.

Performance

ELECTRICAL

Supply Voltage	120 VAC
Maximum Rated Load	Incandescent /halogen 1800W, Ballast 15A standard/ electronic, LED 5A, 1/2 HP motor
Frequency	60Hz
Installation	Single-Pole or 3-Way

MECHANICAL

Enclosure Material	Indoor Use Only
--------------------	-----------------

Materials

Paddle	Polycarbonate	Termination	6", 14 AWG, 105C 600V stranded wires
Back Body	Polycarbonate		

App


Android Requirements	Android 5.0 or higher with camera
Apple IOS Requirements	iOS 10.0 or higher with camera

Radio

Wi-Fi	Certified IEEE 802.11 b/g/n Wi-Fi 2.4GHz radio. Supports IPv4 and IPv6 addressing.
-------	---

Warranty

Limited Lifetime Warranty

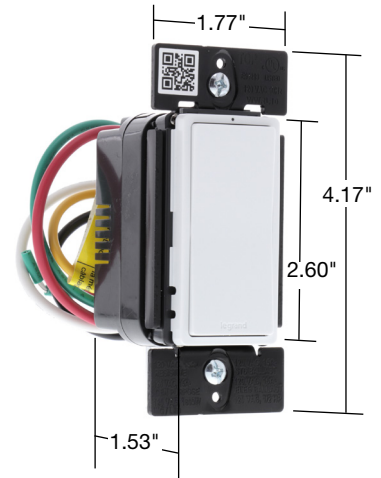

NOTE: All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



NOTE: The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.

**Legrand, North America**

60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

Canada

905.738.9195
www.legrand.ca

FOLLOW US

