



Conveniently control your lights or appliances from anywhere

WWP10

Conveniently control your lights and power from anywhere using the Legrand Smart Lights mobile app, Amazon Alexa, the Google Assistant, and other popular control platforms. In the app, use Scenes to create the perfect ambiance in your home. With automated schedules, sync your lights with sunrise and sunset, or program to simulate occupancy while you're away. Legrand dimmers also use less energy than ordinary switches, with automated options available to promote enhanced energy savings.

Ideal for residential and light commercial applications, the Smart Wi-Fi radiant switch is the simple solution to all your customers' smart lighting requirements.




Android is a trademark of Google LLC.



FEATURES & BENEFITS

- Plug into an open outlet and smart enable any lamp, small appliance or motor up to 1/2 HP
- Works with iOS and Android smart phones for control while at home or halfway around the world
- Schedule lights on/off automatically, group lights, and create Scenes
- Perfect for lamps, fans, coffee makers, and more
- Works with motors up to 1/2 HP
- White LED locator light glows when device is off for easy location in the dark
- Wi-Fi switch is compatible with other standards and has an app available on Android and Apple
- Additional compatibility is Works with Google, Works with Amazon, Its OCF certified, Wi-Fi Certified

COMPLIANCE

 cULus Listed, UL916. File E495025
FCC Class B Part 15, IC. Works with Alexa
Works with the Google Assistant, OCF Certified, Wi-Fi Certified

RoHS Compliant



ORDERING INFORMATION

CATALOG NUMBER	DESCRIPTION	RATING	NEMA	COMPLIANCE	COLORS	COO
WWP10CCV2	Smart Plug-In Switch, Wi-Fi	Incandescent /halogen 1800W, Ballast 15A standard/electronic, LED 5A, 1/2 HP motor	5-15R, 120V		White	China

VERTICAL MARKETS

- Residential

COMPATIBILITY



OPEN CONNECTIVITY
FOUNDATION™



DOWNLOAD THE APP



Smart Light



Download the
iOS Legrand app



Download
the Google
Legrand app

TECHNICAL SPECIFICATIONS

3rd Party Compliance

cULus Listed, UL916. File E495025
 FCC Class B Part 15, IC. Works with Alexa
 Works with the Google Assistant, OCF Certified, Wi-Fi Certified.


Performance

ELECTRICAL

Supply Voltage	120 VAC
Maximum Rated Load	Incandescent /halogen 1800W, Ballast 15A standard/ electronic, LED 5A, 1/2 HP motor
Frequency	60Hz
Installation	Single-Pole or 3-Way

MECHANICAL

Enclosure Material	Indoor Use Only
--------------------	-----------------

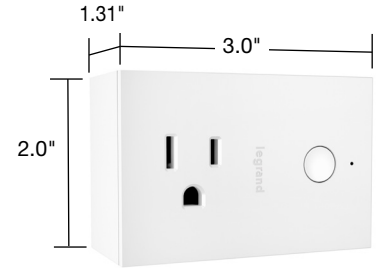

Materials

Paddle	Polycarbonate	Terminal	Brass
Back Body	Polycarbonate		

App

Android Requirements	Android 5.0 or higher with camera
Apple IOS Requirements	iOS 10.0 or higher with camera

Radio

Wi-Fi	Certified IEEE802.11 b/g/n Wi-Fi® 2.4GHz radio. Supports IPv6 addressing to conform to EU standards.
-------	---

Warranty

Limited Lifetime Warranty

NOTE: All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



NOTE: The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.



Legrand, North America

60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

Canada

905.738.9195
www.legrand.ca

FOLLOW US

