

**TSD4FBL3PW**

## A simple solution for 0-10V dimming.

TSD4FBL3P\*

Legrand Dimmers have always been known for style. But now, thanks to customer input, they're known for added simplicity as well. The new 0-10V dimmer controls all the latest LED and fluorescent fixtures in one wall box control (0-10V style fixtures). That means no requirement for a separate power pack.

Interchangeable face covers are available for the dimmers in a variety of popular colors.

Ideal for use in residential and commercial applications, the 0-10V LED and fluorescent dimmer is the simple solution for all your 0-10V control needs.


\*Denotes color suffix

## Features & Benefits

**New aesthetically pleasing ergonomic design** allows for easier operation

**Constant memory** returns lights to previous levels after a power failure

**Screw-pressure-plate backwire terminals** save time, space and money

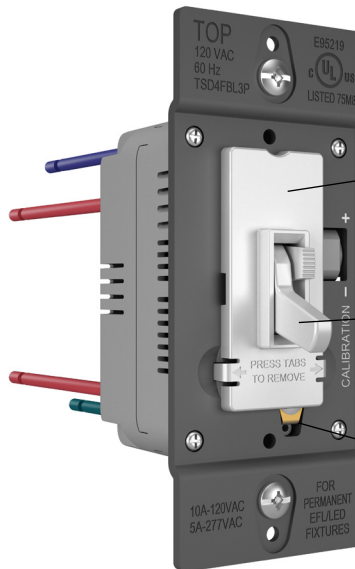

**Interchangeable face plates** available in seven colors (TSDKIT\*; sold separately)

**Convenient operation** – combines ON/OFF toggle switch with separate slider for dimming control

**Trim adjustment** allows users to fine tune dimmer performance to the fixture

**TSD4FBL3PW**

- Preset, Single Pole and 3-Way operation.
- Lifetime warranty.




## 3rd Party Compliance

US cULus listed, UL1472, CSA LISTED

## Technical Information

### Performance

Electrical	
Supply Voltage	120VAC/277VAC
Ratings	120V10A/277V 5A
Frequency	60Hz
Control	0-10VDC 30mA
Installation	Single Pole or 3-Way
Environmental	
Application	Indoor Use Only
Mechanical	

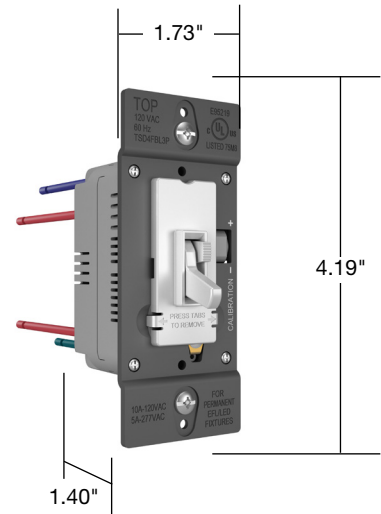

**TSD4FBL3PW**

### Warranty

Lifetime

## Ordering Information

### 0-10V Fluorescent Dimmers

Catalog Number	Description	Color	Voltage	Rating
<b>TSD4FBL3PTC</b>	Preset, Single Pole and 3-Way	Three interchangeable Face Colors: Ivory, White, Light Almond	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3PW</b>	Preset, Single Pole and 3-Way	Face Color: White	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3PLA</b>	Preset, Single Pole and 3-Way	Face Color: Light Almond	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3PI</b>	Preset, Single Pole and 3-Way	Face Color: Ivory	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3P</b>	Preset, Single Pole and 3-Way	Face Color: Brown	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3PBK</b>	Preset, Single Pole and 3-Way	Face Color: Black	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3PRED</b>	Preset, Single Pole and 3-Way	Face Color: Red	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSD4FBL3PGRY</b>	Preset, Single Pole and 3-Way	Face Color: Gray	120VAC 60Hz	120V 10A/ 277V 5A
<b>TSDKIT</b>		Brown		
<b>TSDKITBK</b>		Black		
<b>TSDKITGRY</b>		Gray		
<b>TSDKITI</b>	Interchangeable Faces	Ivory		
<b>TSDKITLA</b>		Light Almond		
<b>TSDKITW</b>		White		
<b>TSDKITRED</b>		Red		

---

## Vertical Markets


- Office
- Residential
- Multiple Dwelling
- Hospitality/Lodging

---

## Available in the radiant® collection

- GFCI Receptacles
- Tamper-Resistant and Standard Duplex Receptacles
- Paddle Switches
- Fan Controls
- Sensors
- Timers
- Home Automation Controls
- USB Charging Devices
- Night Lights
- Screwless Wall Plates

---

 The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



**Legrand, North America**  
60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
[www.legrand.us](http://www.legrand.us)  
905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

