



PlugTail® — The fastest, most consistent and reliable wiring devices – ever.

PT5262, PT5362

Factory-terminated devices and connectors mean that device installation is the same regardless of skill level of the installer. The UL-Listed connectors are keyed to ensure proper wiring installation into each receptacle. The connector simply snaps into the back of the device — no fussing with wires, stripping, or tightening screws. PlugTail devices are finger safe with no exposed terminals, so taping is not required. Now device installation is a snap!

Features & Benefits

Auto-ground clip assures positive ground.



.036 inch thick, brass, triple-wipe power contacts for lasting retention.

Three drive screws anchor strap to back body and face.

Plated steel wrap strap design for maximum durability and corrosion resistance.

Built-in connector features large brass terminal blades to ensure consistent, reliable electrical connections.

Large brass contacts snugly terminate on device blade terminals. Audible snapping latch assures connection, allows release.

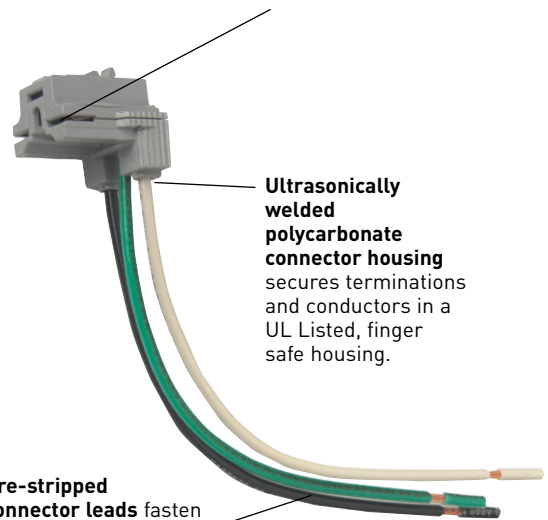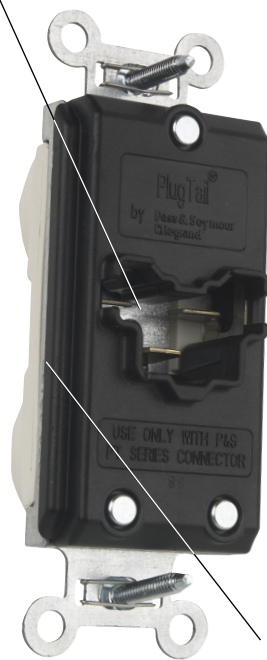

Ultrasonically welded polycarbonate connector housing secures terminations and conductors in a UL Listed, finger safe housing.

Pre-stripped connector leads fasten to conductors, easier than standard pigtails.

No exposed terminals creates a finger safe application before, during, and after installation.

PT5362LA

3rd Party Compliance



cULus Listed, File Number E140596, Standard UL498.
Federal Specification WC596.

Technical Specifications

Performance

Electrical

Dielectric Voltage	Withstands 2000V minimum
Maximum Working Voltage	125V
Current Interrupting	Certified for current interrupting at full-rate current (receptacle only)
Temperature Rise	Maximum 30°C temperature rise at full-rated current after 50 cycles of overload at 150% of rated current with direct current

Mechanical

PlugTail Connector Identification	#12 AWG, THHN, copper conductor, 6" leads, stripped, solid or stranded, for use with PlugTail Receptacles only
Product Identification	Ratings are a permanent part of the device

Environmental

Flammability	UL94 V2
Operating Temperature	Maximum continuous +60°C, minimum -40°C without impact

PlugTail® Receptacle Materials


Face	Nylon
Body	PVC
Contacts	.036 688 Brass
Mounting Strap	.042" Zinc-Plated Steel
Internal Ground System	.036 260 Brass
Assembly Drive Screw	Zinc-Plated Steel
Auto-Ground Clip	Steel
Mounting Screws	Tri-Drive Steel

PlugTail® Connector Materials


Housing	Polycarbonate
Contacts	.030 Brass

Warranty

1 Year

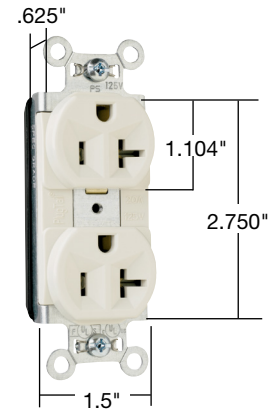

Dimensions for
15 & 20 Amp

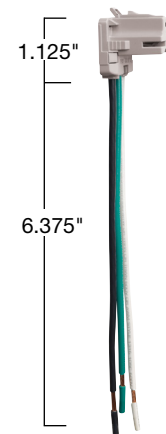

PTR66STR


Ordering Information

PlugTail® Spec Grade Duplex Receptacles & PlugTail Connectors


Catalog Number	Rating		Color	NEMA
	A.	V.		Config. No.
Duplex Receptacles				
PT5262I	15	125	Ivory	5-15R
PT5262W	15	125	White	5-15R
PT5262	15	125	Brown	5-15R
PT5262GRY	15	125	Gray	5-15R
PT5262BL	15	125	Blue	5-15R
PT5262RED	15	125	Red	5-15R
PT5262LA	15	125	Light Almond	5-15R
PT5262BK	15	125	Black	5-15R
PT5362I	20	125	Ivory	5-20R
PT5362W	20	125	White	5-20R
PT5362	20	125	Brown	5-20R
PT5362GRY	20	125	Gray	5-20R
PT5362BL	20	125	Blue	5-20R
PT5362RED	20	125	Red	5-20R
PT5362LA	20	125	Light Almond	5-20R
PT5362BK	20	125	Black	5-20R

PlugTail® Connectors — Right Angle

Catalog Number	Wire Type	Wire Length
PTRA6STR	Stranded	6"
PTRA6SOL	Solid	6"

 


NEMA
5-15R

 

NEMA
5-20R

Also available...

- Hospital Grade Devices
- SPD & Isolated Ground Devices
- Ground Continuity Monitoring (GCM)
- Straight Blade Plugs & Connectors
- Turnlok® Locking Devices
- Weatherproof Boxes & Covers
- IEC 309 Industrial Products
- Flexcor® Wire Mesh Grips
- USB Charging Devices

 The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

570 Applewood Crescent
Vaughan, Ontario L4K 4B4
905.738.9195
www.legrand.ca

FOLLOW US

