



Pass & Seymour

# Straight Blade Plugs & Connectors Heavy-Duty MaxGrip® M<sup>3</sup> 15 & 20A, 125 & 250V

PS5965-Y, PS5965-GRY, PS5965-O, PS5969-Y, PS5969-GRY, PS5969-O,  
PS5364-Y, PS5364-GRY, PS5369-Y, PS5369-GRY, PS5666-Y, PS5669-Y,  
PS5464-Y, PS5469-Y

## Easy assembly and a durable design.

**W**ith their tri-drive assembly and terminal screws in addition to self-hinged nylon housings, MaxGrip M<sup>3</sup> plugs and connectors install quickly and easily. They stay installed, too — because their rugged construction and high-retention cord grips help them shrug off impacts and constant use.



## Features & Benefits

High-visibility yellow and orange, or gray.

**Enclosed terminals** provide solid, internally-clamped connections.

**Molded finger grips** promote safe, sure handling.

**Self-hinge** swings wide open to make quick, easy work of tight, clean connections. Insert conductors into terminals and tighten terminal screws; close hinge housing around cord and tighten housing screws.

PS5965-Y and PS5969-Y

**Tough nylon construction** with crush/impact resistance that exceeds hospital grade and Fed Spec requirements; arc resistance exceeds UL requirements.

## Field Uses/Vertical Markets

- Industrial
- Health Care
- Education
- Institutional
- Retail
- Office
- Hospitality/Lodging
- Multiple Dwelling

SF502R2 – Updated March 2008 – For latest specs visit [www.legrand.us/passandseymour](http://www.legrand.us/passandseymour)

# Straight Blade Plugs & Connectors Heavy-Duty MaxGrip<sup>®</sup> M<sup>3</sup> 15 & 20A, 125 & 250V

## Ordering Information

Catalog Number	Rating A. V.	Description/Color	Cord Diameter	NEMA Config. No.
<b>MaxGrip<sup>®</sup> M<sup>3</sup> Plugs &amp; Connectors</b>				
PS5965-Y	15 125	Plug, Yellow	.230"-.720"	5-15P
PS5965-GRY	15 125	Plug, Gray	.230"-.720"	5-15P
PS5965-O	15 125	Plug, Orange	.230"-.720"	5-15P
PS5969-Y	15 125	Connector, Yellow	.230"-.720"	5-15R
PS5969-GRY	15 125	Connector, Gray	.230"-.720"	5-15R
PS5969-O	15 125	Connector, Orange	.230"-.720"	5-15R
PS5364-Y	20 125	Plug, Yellow	.230"-.720"	5-20P
PS5364-GRY	20 125	Plug, Gray	.230"-.720"	5-20P
PS5369-Y	20 125	Connector, Yellow	.230"-.720"	5-20R
PS5369-GRY	20 125	Connector, Gray	.230"-.720"	5-20R
PS5666-Y	15 250	Plug, Yellow	.230"-.720"	6-15P
PS5669-Y	15 250	Connector, Yellow	.230"-.720"	6-15R
PS5464-Y	20 250	Plug, Yellow	.230"-.720"	6-20P
PS5469-Y	20 250	Connector, Yellow	.230"-.720"	6-20R



NEMA  
5-15R



NEMA  
5-15P



NEMA  
6-15R



NEMA  
6-15P



NEMA  
5-20R



NEMA  
5-20P



NEMA  
6-20R



NEMA  
6-20P

For more information on these and other P&S products refer to our Catalog or visit our web site.

# Straight Blade Plugs & Connectors Heavy-Duty MaxGrip® M<sup>3</sup> 15 & 20A, 125 & 250V



Pass & Seymour

## Technical Specifications

### 3rd Party Compliance

UL Listed, File Number E146159, Standard UL498, Attachment Plugs and Receptacles.  
Federal Specification WC596.  
CSA Certified, File Number LR1765, Standard CSA-C22.2 No. 42, General Use Receptacles and Attachment Plugs.  
Conforms to NEMA WD-1.

### Performance


Electrical	
Dielectric Withstand Voltage	1500V minimum
Maximum Working Voltage	250V
Current Interrupting	Certified for current interrupting at full-rated current
Temperature Rise	30°C maximum after 50 cycles at 150% rated current
Mechanical	
Cord Accommodation	Round portable service cords of diameters in accordance with the device rating as defined in UL62
Cord Grip Accommodation	.22" to .66"; 18/3 SV to 12/3 S cord
Terminal Identification	Green Screw = Ground; Brass Screw = Hot; Silver Screw = Neutral
Terminal Accommodation	#18 AWG min. – #12 AWG max.
Product Identification	Amperage, Voltage, 3rd Party Compliance, NEMA Configuration on side
Environmental	
Flammability Rating	UL94 HB
Operating Temperatures	Maximum continuous +75°C, minimum -40°C without impact

### Materials

Body/Housing	Nylon	Hex Head Ground Screw	Zinc-Plated Steel
Cord Grip Insert	Nylon	Plug Blades	Brass
Terminal Clamp	Brass	Connector Contacts	Brass
Terminal Screws	Nickel- and Brass-Plated Steel	Cord Grip/Assembly Screws	Zinc-Plated Steel

### Warranty

1 Year

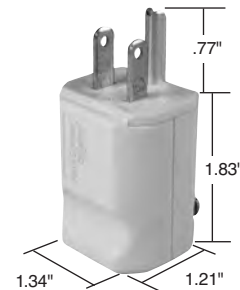

Dimensions for  
MaxGrip® M<sup>3</sup> Plug



Dimensions for  
MaxGrip® M<sup>3</sup> Connector

## Complementary Devices & Accessories




### STRAIGHT BLADE PLUGS & CONNECTORS

- Extra-Hard Use




### GROUND CONTINUITY MONITORING (GCM)

- Extra-Hard Use Straight Blade
- Heavy-Duty Turnlok®

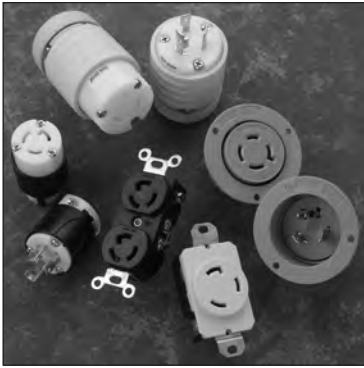

### TURNLOCK® LOCKING DEVICES

- Heavy-Duty Receptacles
- Extra-Hard Use Plugs & Connectors
- Heavy-Duty Flanged Inlets & Outlets

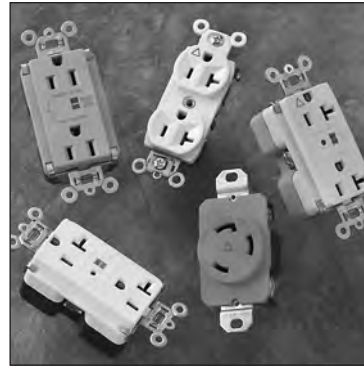

### TVSS & ISOLATED GROUND DEVICES

- Construction Grade Isolated Ground
- Heavy-Duty Turnlok Isolated Ground
- Heavy-Duty Isolated Ground TVSS
- Heavy-Duty TVSS
- Construction Grade TVSS



### IEC 309 INDUSTRIAL PRODUCTS

- Fusible & Non-Fusible Mechanical Interlocks
- Fusible & Non-Fusible Safety Switches
- Pin & Sleeve Devices

## Also available...

- Light Almond Devices
- Decorator Devices
- Hospital Grade Devices
- PlugTail™ Devices
- Switches
- Straight Blade Receptacles
- Lighting & Fan Controls
- GFCIs
- Weatherproof Boxes & Covers
- Wall Plates
- Flexcor® Wire Mesh Grips
- Configurable Solutions



**Legrand/Pass & Seymour**  
P.O. Box 4822  
Syracuse, NY 13221-4822  
800-223-4185

**North America Headquarters**  
60 Woodlawn Street  
West Hartford, CT 06110  
Phone: 1.877.BY.LEGRAND (295.3472)  
Fax: 1.860.232.2062  
www.legrand.us

**Legrand Canada**  
570 Applewood Crescent  
Vaughan, ON, L4K 4B4  
Phone: 905.738.9195  
Fax: 905.738.9721  
www.legrand.ca

SF502R2 - Updated March 2008 - For latest specs visit [www.legrand.us/passandseymour](http://www.legrand.us/passandseymour)