




Pass & Seymour

# Decorator Devices Heavy-Duty Single Receptacles Tamper-Resistant 15 & 20A, 125VAC

TR26261, TR26361

## Sturdy tamper-resistant single receptacles in Decorator style.

Tamper-resistant child safety single receptacles that conform to NEC® Article 406.11 is now available in a Decorator-style. In addition to matching other Decorator devices, this product offers a Federal Specification UL WC596 listing. The sturdy mechanical shutter system helps prevent children from inserting foreign objects into the receptacle. Corrosion-resistant plated steel straps, rugged nylon faces and triple-wipe power contacts combine with tamper-resistant shutters to deliver safe and reliable long-term performance. Screw-pressure-plate back wiring ensures excellent electrical connections and easy installation.

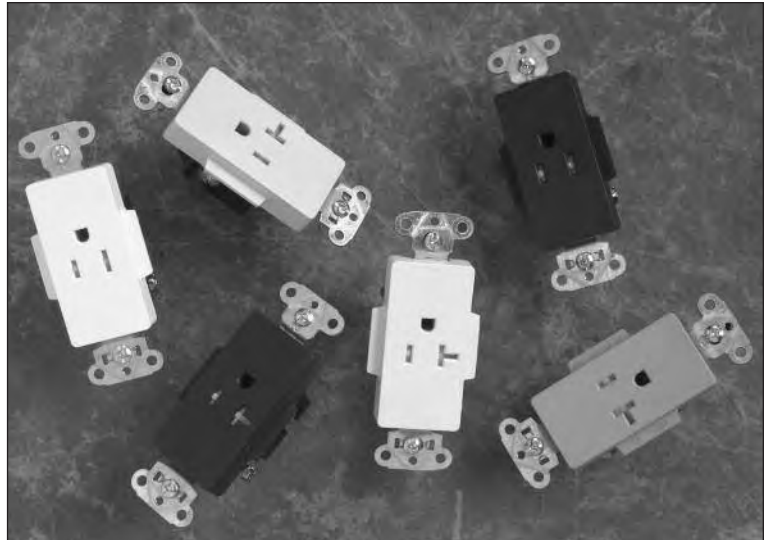

### FEATURES & BENEFITS

**Two drive screws anchor steel strap to back body and face** where abrupt removal torque is greatest.


**Heavy-duty corrosion-resistant zinc-plated steel strap** for added strength.

**One-piece brass triple-wipe power contacts** for lasting retention.

**Dual mechanical shutter system** to help prevent insertion of foreign objects.

**Backed-out tri-drive brass terminal screws for faster installation.** Internal screw-pressure-plate back and side wire capability. Two back wire holes for additional wiring flexibility.

**Auto-ground clip** assures positive ground.

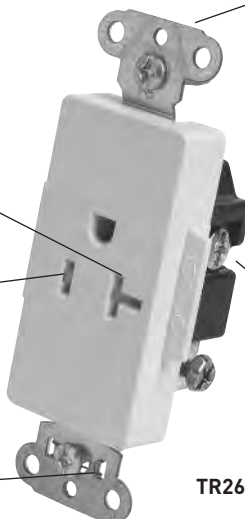

TR26361LA



### FIELD USES/VERTICAL MARKETS

  - Health Care
- Institutional
- Hospitality/Lodging
- Multiple Dwelling

# Decorator Devices Heavy-Duty Single Receptacles Tamper-Resistant 15 & 20A, 125VAC

## ORDERING INFORMATION

Catalog Number	Rating		Color	NEMA Config. No.
	A.	VAC		
<b>Single Decorator Receptacles Back &amp; Side Wire</b>				
TR26261I	15	125	Ivory	5-15R
TR26261W	15	125	White	5-15R
TR26261	15	125	Brown	5-15R
TR26261GRY	15	125	Gray	5-15R
TR26261BK	15	125	Black	5-15R
TR26261LA	15	125	Light Almond	5-15R
TR26361I	20	125	Ivory	5-20R
TR26361W	20	125	White	5-20R
TR26321	20	125	Brown	5-20R
TR26321GRY	20	125	Gray	5-20R
TR26321BK	20	125	Black	5-20R
TR26361LA	20	125	Light Almond	5-20R



For more information on these and other P&S products refer to our Catalog or visit our web site.

# Decorator Devices Heavy-Duty Single Receptacles Tamper-Resistant 15 & 20A, 125VAC



## TECHNICAL SPECIFICATIONS

### 3rd Party Compliance

UL Listed, File Number E140596, Standard UL498.  
Federal Specification WC596.  
CSA Certified Standard CSA-C22.2 No. 42.  
Conforms to NEMA WD-1 and WD-6

### Performance

#### Electrical


Dielectric Voltage	Withstands 2000V minimum
Maximum Working Voltage	125V
Current Interrupting	Certified for current interrupting at full-rated current
Temperature Rise	Maximum 30° C temperature rise at full-rated current after 50 cycles of overload at 150% of rated current with direct current

#### Mechanical

Terminal Identification	Terminal identification in accordance with UL498 (Brass, White, Green)
Terminal Accommodation	#14 – #10 AWG copper conductor only
Product Identification	Ratings are a permanent part of the device

#### Environmental

Flammability	UL92 V2
--------------	---------

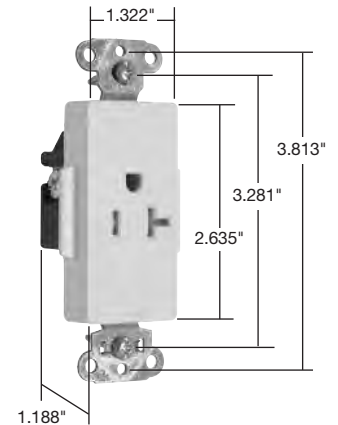

Dimensions for  
15 & 20 Amp


### Materials

Face	Nylon	Terminal Screws	Tri-Drive Brass
Back Body	PVC	Hex Head Grounding Screw	Tri-Drive Zinc-Plated Steel with Green Chromate
Line Contacts	.032 (.8) Brass	Assembly Drive Screws	Zinc-Plated Steel
Mounting Strap	.042 Zinc-Plated Steel	Auto-Ground Clip	Stainless Steel
Clamping Plate	.080 Steel	Mounting Screws	Tri-Drive Steel
Tamper-Resistant Shutters	Thermoplastic		

### Warranty


1 Year

## COMPLEMENTARY DEVICES & ACCESSORIES

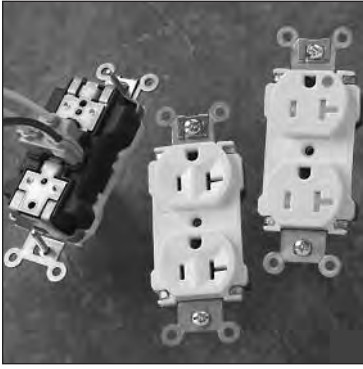


### PLUGTAIL™ DEVICES

- Extra Heavy-Duty Spec Grade
- Extra Heavy-Duty Hospital Grade
- Extra Heavy-Duty Tamper-Resistant

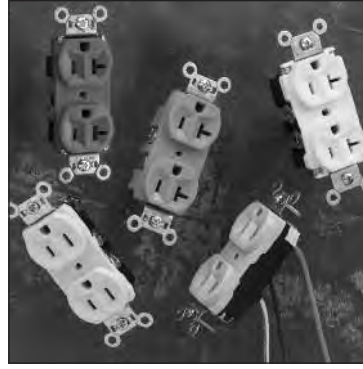


### STRAIGHT BLADE RECEPTACLES

- Extra Heavy-Duty
- Heavy-Duty
- Hard Use
- Construction Grade
- Construction Grade Leaded
- Commercial Grade

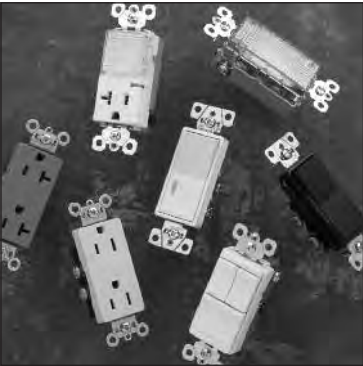


### DECORATOR DEVICES

- Construction Grade Switches
- Specification Grade Combo Switches
- Construction Grade Receptacles
- Commercial Grade Receptacles
- Specification Grade Hallway Lights

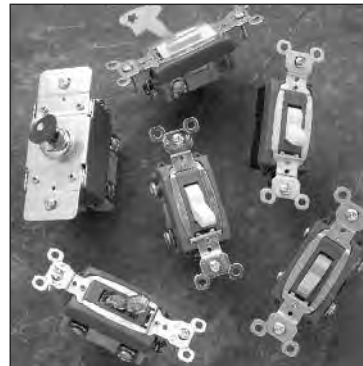

### SWITCHES

- Heavy-Duty Toggle
- Heavy-Duty Lighted Toggle
- Heavy-Duty Security
- Heavy-Duty Locking
- Construction Grade Toggle
- Commercial Grade Toggle

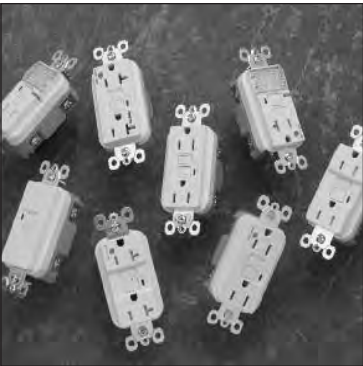

### GFCIs

- Specification Grade



### WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Screwless Polycarbonate
- Stainless Steel
- Brass
- Aluminum
- Dustproof Stainless Steel Covers

## ALSO AVAILABLE...

- |                                      |                                     |                               |                            |
|--------------------------------------|-------------------------------------|-------------------------------|----------------------------|
| ■ Hospital Grade Devices             | ■ Straight Blade Plugs & Connectors | ■ Weatherproof Boxes & Covers | ■ Flexcor® Wire Mesh Grips |
| ■ TVSS & Isolated Ground Devices     | ■ Turnlok® Locking Devices          | ■ IEC 309 Industrial Products | ■ Bulk Solutions           |
| ■ Ground Continuity Monitoring (GCM) |                                     |                               |                            |



**Legrand/Pass & Seymour**  
P.O. Box 4822  
Syracuse, NY 13221-4822  
800-223-4185

**North America Headquarters**  
60 Woodlawn Street  
West Hartford, CT 06110  
Phone: 1.877.BY.LEGRAND (295.3472)  
Fax: 1.860.232.2062  
www.legrand.us

**Legrand Canada**  
570 Applewood Crescent  
Vaughan, ON, L4K 4B4  
Phone: 905.738.9195  
Fax: 905.738.9721  
www.legrand.ca

