




Pass & Seymour

# Straight Blade Receptacles Construction Grade Single Tamper-Resistant 15 & 20A, 125V

TR5251, TR5351

## Rugged construction plus tamper-resistance equals one safe receptacle


**T**amper-resistant child safety outlets that conform to 2008 NEC® Article 406.11 are now available as a specification grade single receptacle. The sturdy mechanical shutter system helps prevent children from inserting foreign objects into the receptacle. Corrosion-resistant plated steel straps, rugged nylon faces and triple-wipe power contacts combine with tamper-resistant shutters to deliver safe and reliable long-term performance. Tri-drive mounting and backed out terminal screws combine to save installation time.

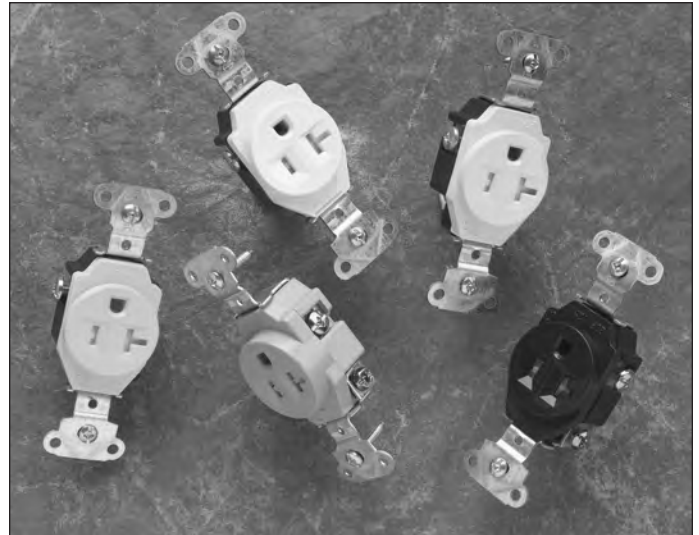

### Features & Benefits

**Dual mechanical shutter system** to help prevent insertion of foreign objects.

**One-piece brass triple-wipe power contacts** for lasting retention.

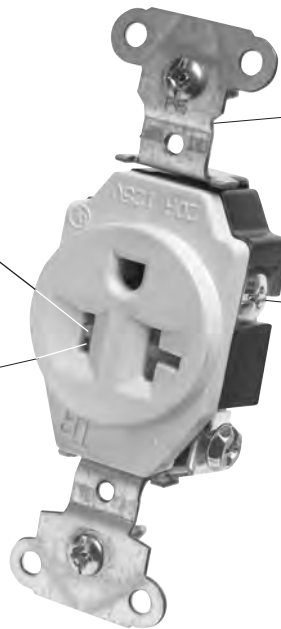

**Heavy-duty, corrosion-resistant zinc-plated steel strap** for added strength.

**Backed-out tri-drive steel terminal screws. Internal screw-pressure-plate back and side wire capability. Two back wire holes** for increased wiring flexibility.

Two drive screws anchor steel strap to back body and face where abrupt removal torque is greatest.

TR5351-LA

### Field Uses/Vertical Markets

■ Retail

■ Office

■ Hospitality/Lodging

■ Multiple Dwelling

SF312R1 — Updated March 2008 — For latest specs visit [www.legrand.us/passandseymour](http://www.legrand.us/passandseymour)



Pass & Seymour

# Straight Blade Receptacles Construction Grade Single Tamper-Resistant 15 & 20A, 125V

## Ordering Information

Catalog Number	Rating		Color	NEMA Config. No.
	A.	V.		
<b>Single Receptacles Back &amp; Side Wire</b>				
TR5251-I	15	125	Ivory	5-15R
TR5251-W	15	125	White	5-15R
TR5251	15	125	Brown	5-15R
TR5251-LA	15	125	Light Almond	5-15R
TR5351-I	20	125	Ivory	5-20R
TR5351-W	20	125	White	5-20R
TR5351-LA	20	125	Light Almond	5-20R



NEMA  
5-15R



NEMA  
5-20R

For more information on these and other P&S products refer to our Catalog or visit our web site.

SF312R1 — Updated March 2008 — For latest specs visit [www.legrand.us/passandseymour](http://www.legrand.us/passandseymour)

# Straight Blade Receptacles Construction Grade Single Tamper-Resistant 15 & 20A, 125V



Pass & Seymour

## Technical Specifications


### 3rd Party Compliance

UL Listed, File Number E140596, Standard UL498; Federal Specification WC596; CSA Certified, Standard CSA-C22.2 No. 42.



### Performance

<b>Electrical</b>	
Dielectric Voltage	Withstands 2000V minimum
Maximum Working Voltage	125V
Current Interrupting	Certified for current interrupting at full-rated current
Temperature Rise	Maximum 30°C temperature rise at full-rated current after 50 cycles of overload at 150% of rated current with direct current
<b>Mechanical</b>	
Terminal Identification	Terminal identification in accordance with UL498 (Brass, White, Green)
Terminal Accommodation	#14 - #10 AWG copper conductor only
Product Identification	Ratings are a permanent part of the device
<b>Environmental</b>	
Flammability	UL94 V2

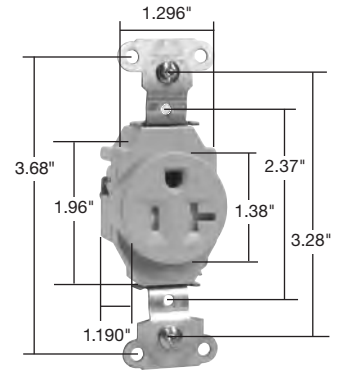

**Dimensions for  
15 & 20 Amp**


### Materials

Face	Nylon	Terminal Screws	Tri-Drive Brass
Back Body	PVC	Hex Head Grounding Screw	Tri-Drive Zinc
Contacts	.032 (.8) Brass		Plated Steel
Clamping Plate	.080 Steel	Assembly Rivets	Steel
Mounting Strap	.042 Steel	Mounting Screws	Tri-Drive Steel

**Warranty**


1Year

## Complementary Devices & Accessories

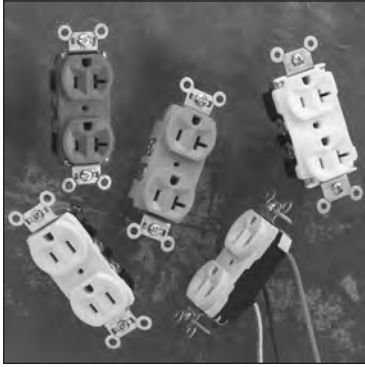


### STRAIGHT BLADE RECEPTACLES

- Extra Heavy-Duty
- Heavy-Duty
- Hard Use
- Construction Grade
- Construction Grade Leaded
- Commercial Grade

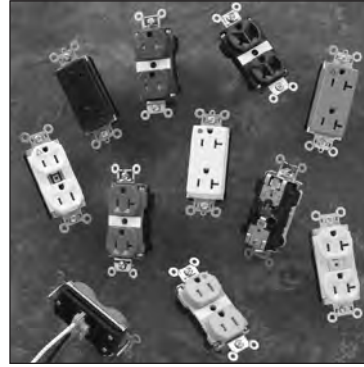


### PLUGTAIL™ DEVICES

- Extra Heavy-Duty Spec Grade
- Extra Heavy-Duty Hospital Grade
- Extra Heavy-Duty Tamper-Resistant
- Extra Heavy-Duty Tamper-Resistant Hospital Grade

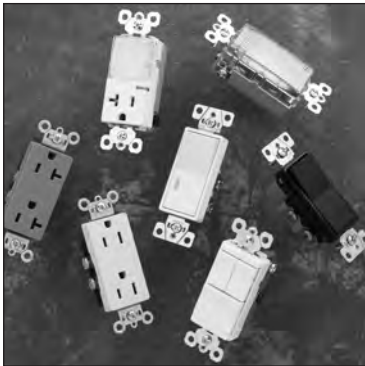


### DECORATOR DEVICES

- Construction Grade Switches
- Specification Grade Combo Switches
- Construction Grade Receptacles
- Commercial Grade Receptacles
- Specification Grade Hallway Lights

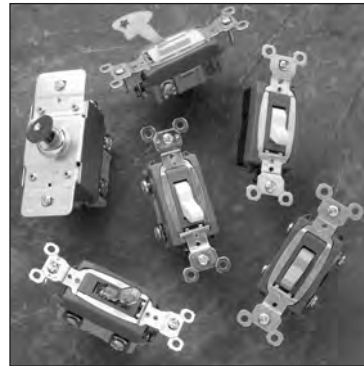

### SWITCHES

- Extra Heavy-Duty
- Extra Heavy-Duty Lighted
- Extra Heavy-Duty Security
- Extra Heavy-Duty Locking
- Hard Use
- Commercial Grade

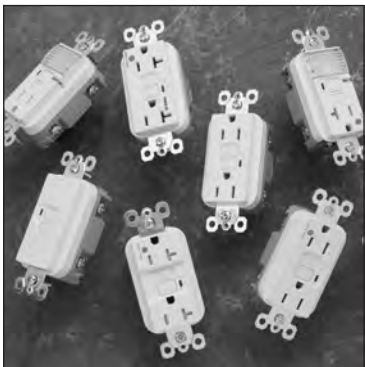

### GFCIs

- Specification Grade
- Hospital Grade
- PlugTail™



### WALL PLATES

- TradeMaster® Thermoplastic Nylon
- Screwless Polycarbonate
- Stainless Steel
- Brass
- Aluminum
- Dustproof Stainless Steel Covers

## Also available...

- Light Almond Devices
- Hospital Grade Devices
- TVSS & Isolated Ground Devices
- Lighting & Fan Controls
- Ground Continuity Monitoring (GCM)
- Straight Blade Plugs & Connectors
- Turnlok® Locking Devices
- Weatherproof Boxes & Covers
- IEC 309 Industrial Products
- Flexcor® Wire Mesh Grips
- Configurable Solutions



**Legrand/Pass & Seymour**  
 P.O. Box 4822  
 Syracuse, NY 13221-4822  
 800-223-4185

**North America Headquarters**  
 60 Woodlawn Street  
 West Hartford, CT 06110  
 Phone: 1.877.BY.LEGRAND (295.3472)  
 Fax: 1.860.232.2062  
 www.legrand.us

**Legrand Canada**  
 570 Applewood Crescent  
 Vaughan, ON, L4K 4B4  
 Phone: 905.738.9195  
 Fax: 905.738.9721  
 www.legrand.ca