


1307 VERTICAL ADJUSTABLE SPLICE

VERTICAL ADJUSTABLE SPLICE G T

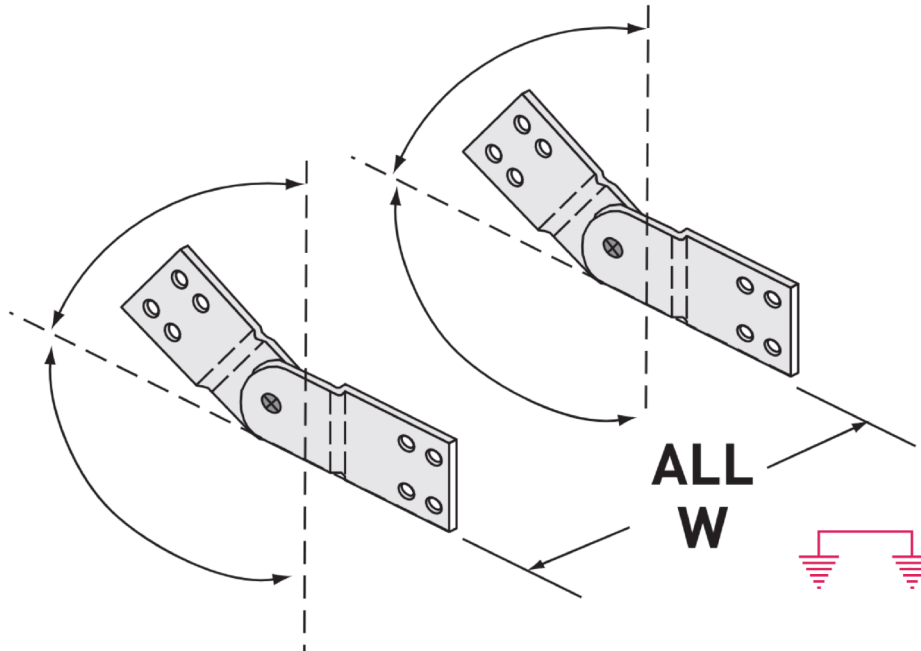

Maximum bend angle is ± 90

CONNECTOR DESIGNED TO FIT BOTH SERIES 1 & 2 SYSTEMS. WHEN ORDERING, HOWEVER, THEY SHOULD BE SPECIFIED AS SERIES 2.

PRODUCT NUMBER	FASTENER OPTIONS
1307	GE S6
CATALOG NUMBERING EXAMPLE:	
Connector System No. 4 G 2 -	Fasteners 1307 - GE

The symbol indicates that bonding jumpers are required.

- **Material:** Hot-Dipped Galvanized (G), 316L Stainless Steel (T)
- **Fasteners:** Geomet (GE), 316L Stainless Steel (S6)
- **Height (H):** Tray height: 4", 5", 6", 7"
- **Torque:** 19 - 25 ft-lbs