



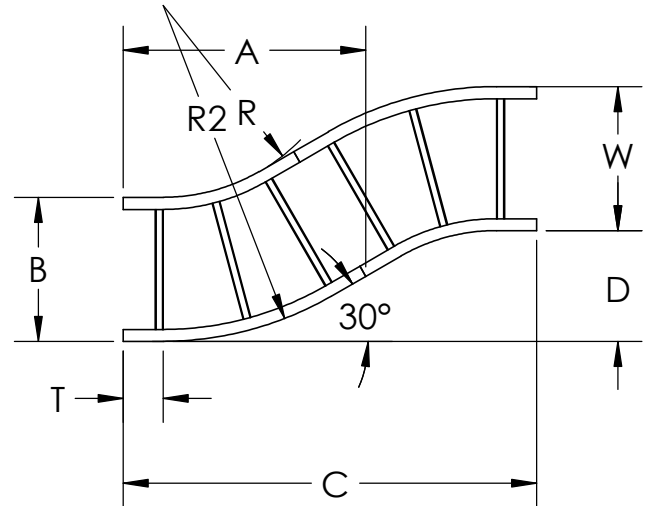

PW Steel Ladder Cable Tray Horizontal Fitting

30HB Horizontal 30° Elbow

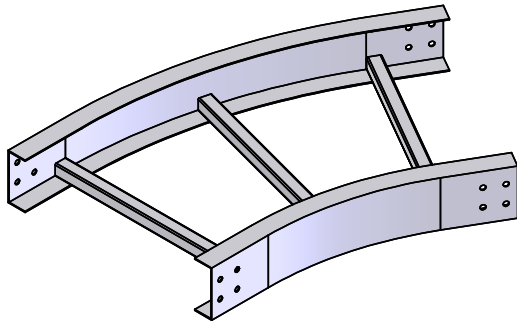

HORIZONTAL ELBOW CATALOG NUMBERING EXAMPLE									
FITTING									
SYSTEM NO. PRODUCT NO.									
BOTTOM TYPE		LD - 4G2I - 3024 - 18						WIDTH	
VENTED								06 - 6"	
LD - Ladder								09 - 9"	
VC! - Vented Corrugated								12 - 12"	
NON-VENTED								18 - 18"	
SC! - Solid Corrugated								24 - 24"	
SF! - Solid Flat Bottom								30 - 30"	
! Available for flange in only								36 - 36"	
VC/SC Available in steel only									
SF Available in stainless steel only									

MATERIAL: STEEL/STAINLESS STEEL

FINISH SUFFIX:

G: HOT DIP GALVANIZED STEEL PER ASTM A123

L: 304 STAINLESS STEEL PER ASTM A-240

T: 316 STAINLESS STEEL PER ASTM A-240

BOTTOM: LD - LADDER

VC - VENTED CORRUGATED

SC - SOLID CORRUGATED

SF - SOLID FLAT BOTTOM

Construction: Welded

Tray Design: Tray constructed and markings are per the latest addition of NEMA Standards Publication VE1, CSA C22.2 No. 126

Connectors: All fittings are supplied with necessary connectors and fasteners

Fitting Heights (H): 4", 5", 6", 7"

Tangents: Series 1 fittings have a 2" tangent
Series 2 fittings have a 5" tangent

PRODUCT NUMBER RADIUS (IN.)	W	R2	SERIES1				SERIES2			
			A	B	C	D	A	B	C	D
3012 12"	6	18	12 ¹ / ₄	8 ⁵ / ₈	22 ¹ / ₂	6	18 ³ / ₈	10 ¹ / ₈	33 ¹ / ₄	9
	9	21	14 ¹ / ₄	11 ³ / ₈	24	6 ³ / ₈	19 ¹ / ₈	13 ³ / ₈	35 ¹ / ₄	9 ¹ / ₂
	12	24	15 ³ / ₄	14 ³ / ₈	25 ¹ / ₂	6 ⁷ / ₈	21 ¹ / ₈	16 ¹ / ₈	36 ³ / ₄	9 ³ / ₈
	18	30	18 ³ / ₄	20 ³ / ₈	28 ¹ / ₂	7 ¹ / ₈	24 ³ / ₈	22 ¹ / ₈	39 ³ / ₄	10 ¹ / ₈
	24	36	21 ¹ / ₄	26 ³ / ₈	31 ¹ / ₂	8 ³ / ₈	27 ³ / ₈	28 ¹ / ₈	42 ³ / ₄	11 ¹ / ₂
	30	42	24 ¹ / ₄	32 ³ / ₈	34 ¹ / ₂	9 ¹ / ₄	30 ³ / ₈	34 ¹ / ₈	45 ³ / ₄	12 ¹ / ₈
3024 24"	6	30	18 ³ / ₄	10 ¹ / ₄	34 ¹ / ₂	9 ¹ / ₄	24 ³ / ₈	11 ¹ / ₄	45 ³ / ₄	12 ¹ / ₄
	9	33	20 ¹ / ₄	13 ¹ / ₄	36	9 ⁵ / ₈	25 ¹ / ₈	14 ¹ / ₄	47 ¹ / ₄	12 ⁵ / ₈
	12	36	21 ¹ / ₄	16 ¹ / ₄	37 ¹ / ₂	10 ¹ / ₈	27 ¹ / ₈	17 ¹ / ₄	48 ³ / ₄	13
	18	42	24 ¹ / ₄	22 ¹ / ₄	40 ¹ / ₂	10 ³ / ₈	30 ³ / ₈	23 ¹ / ₄	51 ³ / ₄	13 ³ / ₈
	24	48	27 ¹ / ₄	28 ¹ / ₄	43 ¹ / ₂	11 ¹ / ₈	33 ³ / ₈	29 ¹ / ₄	54 ³ / ₄	14 ¹ / ₈
	30	54	30 ¹ / ₄	34 ¹ / ₄	46 ¹ / ₂	12 ¹ / ₂	36 ³ / ₈	35 ¹ / ₄	57 ³ / ₄	15 ¹ / ₈
3036 36"	6	42	24 ¹ / ₄	11 ³ / ₈	46 ¹ / ₂	12 ¹ / ₂	30 ³ / ₈	13 ³ / ₈	57 ³ / ₄	15 ¹ / ₂
	9	45	26 ¹ / ₄	14 ³ / ₈	48	12 ³ / ₈	31 ¹ / ₈	16 ³ / ₈	59 ¹ / ₄	15 ³ / ₈
	12	48	27 ¹ / ₄	17 ³ / ₈	49 ¹ / ₂	13 ¹ / ₈	33 ³ / ₈	19 ¹ / ₈	60 ³ / ₄	16 ¹ / ₄
	18	54	30 ¹ / ₄	23 ³ / ₈	52 ¹ / ₂	14 ¹ / ₈	36 ³ / ₈	25 ¹ / ₈	63 ³ / ₄	17
	24	60	33 ¹ / ₄	29 ³ / ₈	55 ¹ / ₂	14 ³ / ₈	39 ³ / ₈	31 ¹ / ₈	66 ³ / ₄	17 ³ / ₈
	30	66	36 ¹ / ₄	35 ³ / ₈	58 ¹ / ₂	15 ¹ / ₄	42 ³ / ₈	37 ¹ / ₈	69 ³ / ₄	18 ¹ / ₄
36	72	39 ¹ / ₄	41 ³ / ₈	61 ¹ / ₂	16 ¹ / ₂	45 ³ / ₈	43 ¹ / ₈	72 ³ / ₄	19 ¹ / ₂	

"Copyright LNA, Inc. Drawings are proprietary and may not be copied or otherwise duplicated or used without express written permission."

CABCS1500

Legrand
8319 State Rt. 4
Mascoutah, IL 62258 USA
800-658-4641
618-566-3250
Fax 618-566-4978
www.legrand.us/cablofil