

EZ Patch™

A BETTER WAY TO PATCH

designed to be better.™



Loaded EZ Patch Flat Pack,
available in Clarity or
Reduced Diameter cords

The next generation of EZ Patch solutions...

Built on over ten years of packaging innovation, the EZ Patch suite of patch cord solutions delivers efficiencies by reducing installation time and limiting packaging waste.

EZ Patch boxes, available in both Clarity and Reduced Diameter options, provide a “tissue box” like dispensing solution, eliminating tie wraps and cord memory; the cords dispense one after another, ready to install. The next generation of EZ Patch solutions, EZ Patch Flat Pack. This enhancement provides bulk packaged Clarity or Reduced Diameter patch cords straight and flat, offering a quick and convenient way to introduce new cabling to a data center or building network while enabling a cleaner, dust-free application when cardboard is prohibited in the data center. Together, EZ Patch solutions provide a better way to patch.



EZ Patch Clarity Flat Pack,
EZFFPM609Q12-06



EZ Patch Boxes & Reduced Diameter Boxes,
EZC6A05Q50-05



EZ Patch Flat Pack

The **EZ Patch Flat Pack** is an innovative addition to the EZ Patch series, allowing 12 cords to be distributed from flat plastic packaging, which is ideal for patch panel applications or installations on the go.

EZ Patch Flat Packs are bagged with patch cords straight and flat, offering a quick and convenient way to introduce new cabling to a data center or building network. This bagged option allows for a cleaner, dust-free application when cardboard is prohibited in the data center. Cord memory is no longer an issue, with the packs laid out flat in a bundle. Having perforated tear strips provides quick connectivity options and improves cable management during installation. Overall, the Flat Pack means faster installation, less packaging waste and no more zip ties.

FEATURES:

- **Bulk packaging:** Reduces installation time and packaging waste. No dealing with individual bags or zip ties.
- **No cord memory:** Packs are laid out flat in a bundle. Cords are ready to install in a clean bundle without any bends or kinks from packaging.
- **Plastic packaging:** Ideal for data center applications that do not allow cardboard.
- **Light weight design:** Installers can easily carry the bag over their shoulder.
- **Easy tear perforation strips:** Tears at each end allow for quick connection and easy bag removal from the bundle.
- **Cable management:** The bag can be used as a fishing mechanism to route a bundle through a vertical manager.

EZFP Clarity Cords: EZFPM aa bb Q xx - yy

<p>aa</p> <p>6 = CAT 6 6A = CAT6A</p>	<p>bb</p> <table style="width: 100%; border: none;"> <tr> <td>03 = 3'</td> <td>09 = 9'</td> <td>15 = 15'</td> </tr> <tr> <td>05 = 5'</td> <td>10 = 10'</td> <td>20 = 20'</td> </tr> <tr> <td>07 = 7'</td> <td>12 = 12'</td> <td>25 = 25'</td> </tr> </table>	03 = 3'	09 = 9'	15 = 15'	05 = 5'	10 = 10'	20 = 20'	07 = 7'	12 = 12'	25 = 25'	<p>xx</p> <p>12 = 12 Cords</p>	<p>yy</p> <table style="width: 100%; border: none;"> <tr> <td>00 = Black</td> <td>04 = Yellow</td> <td>08 = Gray</td> </tr> <tr> <td>02 = Red</td> <td>05 = Green</td> <td>09 = White</td> </tr> <tr> <td>03 = Orange</td> <td>06 = Blue</td> <td>07 = Violet</td> </tr> </table>	00 = Black	04 = Yellow	08 = Gray	02 = Red	05 = Green	09 = White	03 = Orange	06 = Blue	07 = Violet
03 = 3'	09 = 9'	15 = 15'																			
05 = 5'	10 = 10'	20 = 20'																			
07 = 7'	12 = 12'	25 = 25'																			
00 = Black	04 = Yellow	08 = Gray																			
02 = Red	05 = Green	09 = White																			
03 = Orange	06 = Blue	07 = Violet																			

Example: EZFPM6A05Q12-06 EZ Patch Flat Pack, Clarity, CAT6A, 5ft, 12 Pack, Blue

EZFP RDC 28AWG Cords: EZFPR aa bb Q xx - yy

<p>aa</p> <p>6 = CAT 6 6A = CAT6A</p>	<p>bb</p> <table style="width: 100%; border: none;"> <tr> <td>03 = 3'</td> <td>09 = 9'</td> <td>15 = 15'</td> </tr> <tr> <td>05 = 5'</td> <td>10 = 10'</td> <td>20 = 20'</td> </tr> <tr> <td>07 = 7'</td> <td>12 = 12'</td> <td>25 = 25'</td> </tr> </table>	03 = 3'	09 = 9'	15 = 15'	05 = 5'	10 = 10'	20 = 20'	07 = 7'	12 = 12'	25 = 25'	<p>xx</p> <p>12 = 12 Cords</p>	<p>yy</p> <table style="width: 100%; border: none;"> <tr> <td>00 = Black</td> <td>04 = Yellow</td> <td>08 = Gray</td> </tr> <tr> <td>02 = Red</td> <td>05 = Green</td> <td>09 = White</td> </tr> <tr> <td>03 = Orange</td> <td>06 = Blue</td> <td>07 = Violet</td> </tr> </table>	00 = Black	04 = Yellow	08 = Gray	02 = Red	05 = Green	09 = White	03 = Orange	06 = Blue	07 = Violet
03 = 3'	09 = 9'	15 = 15'																			
05 = 5'	10 = 10'	20 = 20'																			
07 = 7'	12 = 12'	25 = 25'																			
00 = Black	04 = Yellow	08 = Gray																			
02 = Red	05 = Green	09 = White																			
03 = Orange	06 = Blue	07 = Violet																			

Example: EZFPR615Q12-08 EZ Patch Flat Pack, 28AWG, CAT6, 15ft, 12 Pack, Gray




EZ Patch Boxes

The **EZ Patch** solution is a revolutionary way to dispense and manage patch cords, reducing installation time and waste. There are no bags to open, tie wraps to undo, or straightening necessary; the cords dispense one after another, ready to install. With EZ Patch, staging areas are clean, neat, and completely organized.

EZ Patch uses an innovative clip to connect patch cords, allowing cords to be distributed over an internal cardboard reel and fed through the front box opening. The corrugated cardboard box and internal dispensing reel are made from 100% recyclable materials, and the clip is made from 25% regrind plastic. Each of these components is fully recyclable after use, making the EZ Patch solution a contributor towards LEED certification.

FEATURES:

- **Dispenses patch cords quickly & easily:** Reduces staging and installation time.
- **Eliminates trash from opening bags:** A green, friendly approach to packaging patch cords.
- **Provides a more orderly staging approach:** Eliminates errors and tangles from traditional staging.
- **Factory tested** and ETL third-party tested and verified to TIA/EIA 568C.2
- **Par align two pair-positioning technology:** Maintains pair integrity through the plug termination, allowing mating hardware to be designed/tuned to these cords.
- **Snagless plug design:** Protects plugs when pulling through pathways or cable managers.
- **Premium conductor cordage:** Reliable performance and durable cord life.

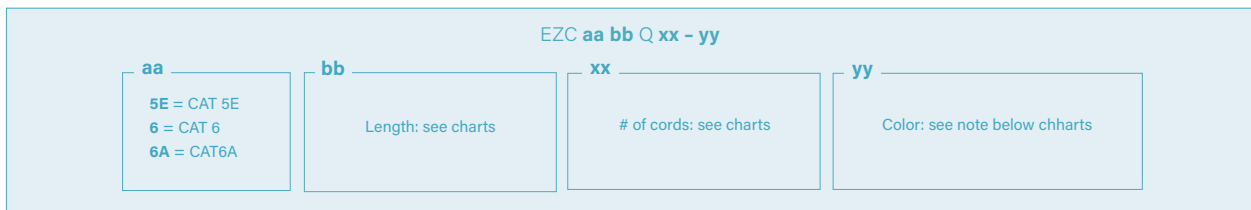

CAT 5E

Length "bb" Ranges	QTY "xx"
"01" to "02" = 1-2 FT	100
"03" to "07" = 3-7 FT	50
"08" to "12" = 8-12 FT	40
"13" to "15" = 13-15 FT	25

For color options replace "YY" suffix: -09 = White, -08 = Gray, -06 = Blue, -05 = Green, -04 = Yellow, -03 = Orange

Contact Customer Service for availability

CAT 6

Length "bb" Ranges	QTY "xx"
"01" to "02" = 1-2 FT	100
"03" to "07" = 3-7 FT	50
"08" to "12" = 8-12 FT	40
"13" to "15" = 13-15 FT	25

For quantity greater than 99 add an extra digit to part # (EX. Q100 = Quantity 100).

For color options replace "YY" suffix: -11 = Pink, -09 = White, -08 = Gray, -07 = Purple, -06 = Blue, -05 = Green, -04 = Yellow, -03 = Orange, -02 = Red, -00 = Black

Contact Customer Service for availability

CAT 6A

Length "bb" Ranges	QTY "xx"
"01" to "02" = 1-2 FT	75
"03" to "05" = 3-5 FT	50
"06" to "07" = 6-7 FT	40
"08" to "11" = 8-11 FT	30
"12" to "13" = 12-13 FT	25
"14" to "15" = 14-15 FT	20

For color options replace "YY" suffix: -09 = White, -07 = Purple, -06 = Blue, -05 = Green, -02 = Red, -00 = Black

Contact Customer Service for availability



EZ Patch Reduced Diameter Boxes

The **EZ Patch Reduced Diameter** patch cable is the perfect solution for high-density applications. Reduced Diameter Cords provide a smaller cable surface area allowing for increased airflow compared to standard networking cables. The 28AWG OD allows for a smaller bend radius than standard networking cables. The flexible design of the RDC cords allows it to be easily routed through cable management accessories.

FEATURES:

- **Dispenses patch cords quickly & easily:** Reduces staging and installation time.
- **Eliminates trash from opening bags:** A green, friendly approach to packaging patch cords.
- **Provides a more orderly staging approach:** Eliminates errors and tangles from staging.
- **Each cord is factory tested:** Ensures every cord shipped meets Category 6 and 6A channel specifications.
- **Reduced diameter mini patch cord:** takes up less cable management space and leaves more space for airflow.
- **Premium plug designed for reduced OD 28 AWG patch cable:** Protects performance integrity through the plug termination.
- **Snagless plug design:** Protects plugs when pulling through cable managers or pathways.
- **Premium 28 AWG conductor cordage:** Reliable performance and durable cord life.
- **Compatible with both T568A and T568B wiring:** Provides universal wiring ability.
- **Backward compatible to Category 3, 5, and 5e:** Supports lower category installations and components.

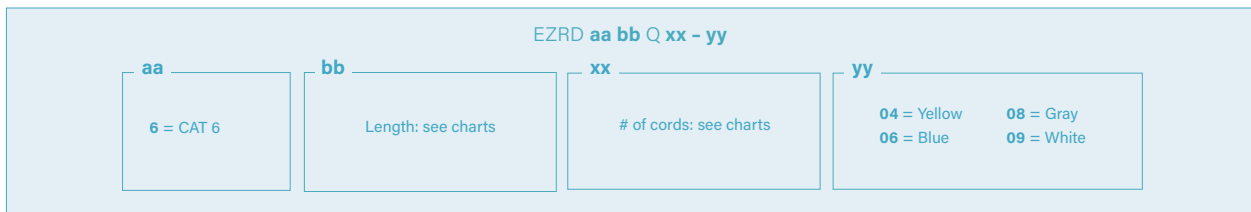


TABLE 1

Length "bb" Ranges	QTY "xx"
"01" to "03" = 1-3 FT	100
"04" to "05" = 4-5 FT	90
"06" to "07" = 6-7 FT	80
"08" to "10" = 8-10 FT	70
"11" to "20" = 11-20 FT	50

Standard configurations shown. Note: For quantity greater than 99 add an extra digit to part # (EX. Q100 = Quantity 100).



Data Power Control

60 Woodlawn Street
West Hartford, CT 06110
800.934.5432
www.legrand.us

FOLLOW US

